

TECHSPEC[®] 125mm, Center Drive, Standard Top, Metric Extended Micrometer



TECHSPEC[®] Crossed-Roller Bearing Linear Translation Stages (Standard-Top Model)



Stock #66-458 1 In Stock

-

1

+

S\$1,190^{.00}

ADD TO CART

Volume Pricing	
Qty 1-2	S\$1,190.00 each
Qty 3+	S\$1,041.74 each
Need More?	Request Quote

Product Downloads

General

Type:


Metric

Physical & Mechanical Properties


Type of Movement:

Linear (X)


Guide System:

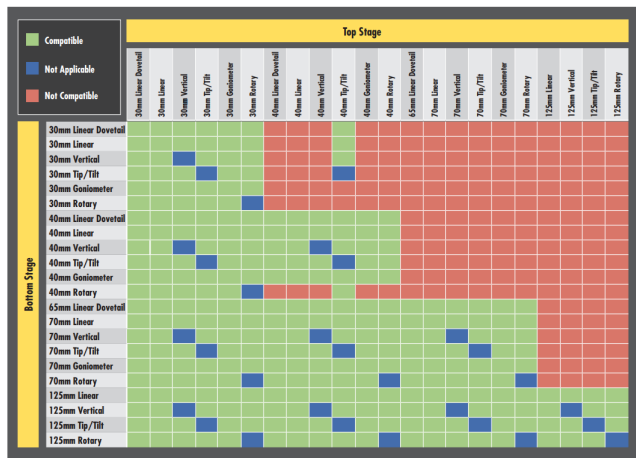


30mm Standard-Top Stages - Center Drive

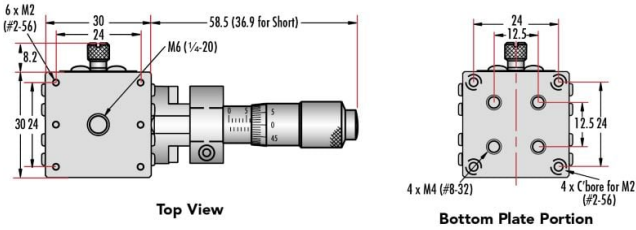


30mm Standard-Top Stages - Side Drive

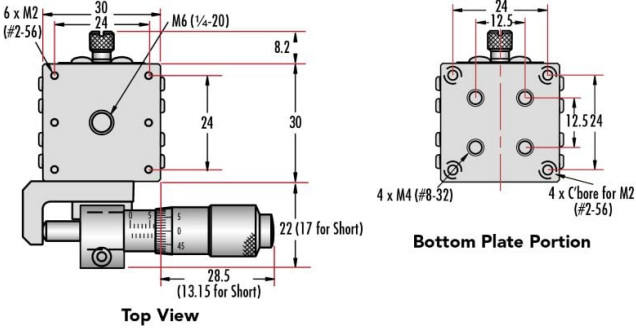


40mm Standard-Top Stages - Center Drive

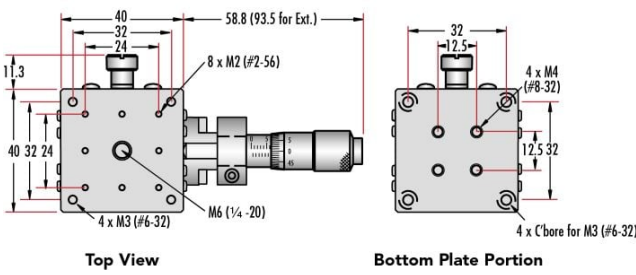


40mm Standard-Top Stages - Side Drive

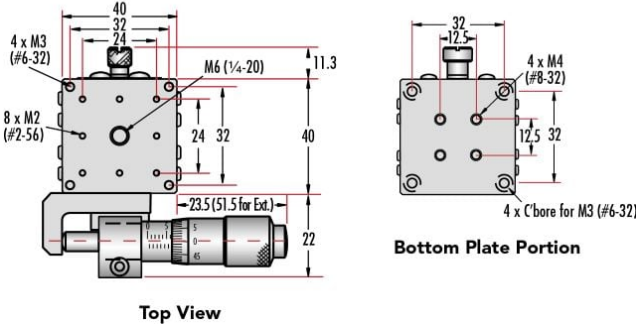


70mm Standard-Top Stages - Center Drive

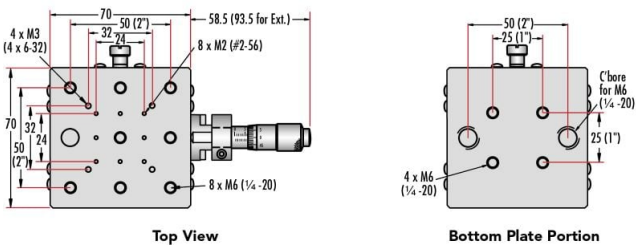

70mm Standard-Top Stages - Side Drive

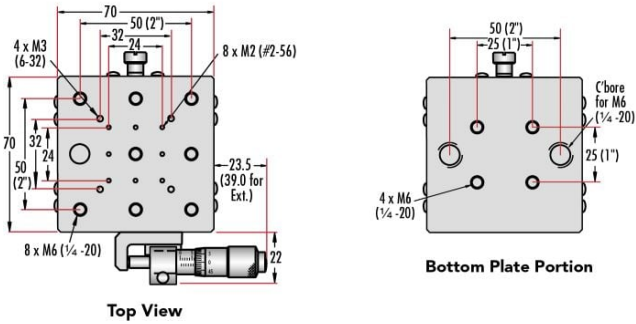

125mm Standard-Top Stages - Center Drive

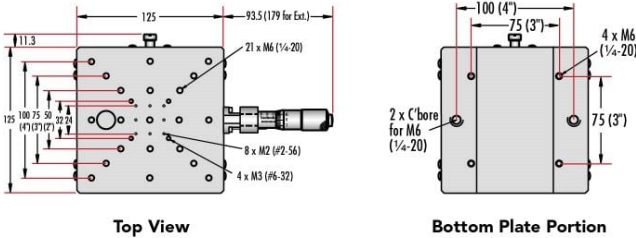

125mm Standard-Top Stages - Side Drive

