

TECHSPEC[®] 125mm, Center Drive, Standard Top, Metric Micrometer Stage



TECHSPEC[®] Crossed-Roller Bearing Linear Translation Stages (Standard-Top Model)



+2

Stock **#66-457** [CONTACT US](#)

-

1

+

S\$987⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	S\$987.00 each
Qty 3+	S\$861.14 each
Need More?	Request Quote

Product Downloads

General

Type:


Metric

Physical & Mechanical Properties

Type of Movement:

Linear (X)

Guide System:

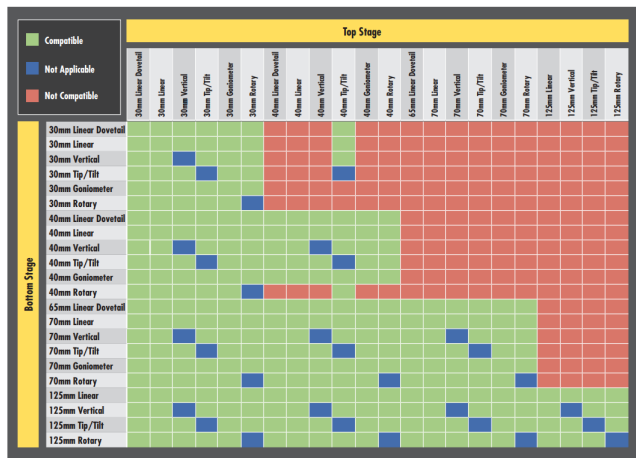

30mm Standard-Top Stages - Center Drive



30mm Standard-Top Stages - Side Drive



40mm Standard-Top Stages - Center Drive



40mm Standard-Top Stages - Side Drive



70mm Standard-Top Stages - Center Drive



70mm Standard-Top Stages - Side Drive



125mm Standard-Top Stages - Center Drive



125mm Standard-Top Stages - Side Drive

