


203.2 x 254 x 3mm High Efficiency Window

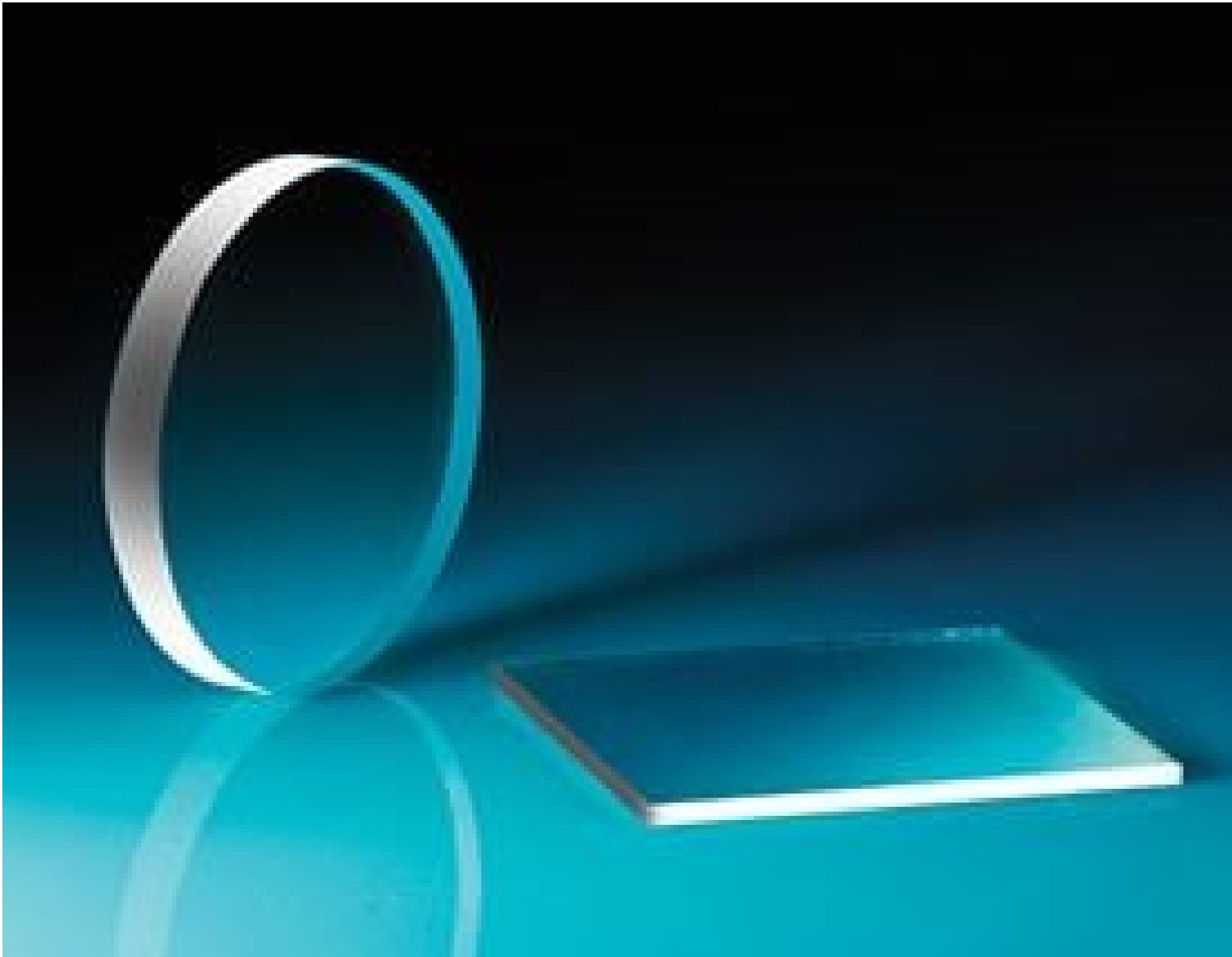

Stock #43-974 3-5 DAYS

- 1 +

S\$87.00

ADD TO CART

Qty 1-5

S\$87.00

Qty 6+

S\$69.60

Volume Pricing

[Request Quote](#)

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm):

182.88 x228.6
Dimensions (mm): 203.20 x254.00
Thickness (mm): 3.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: R _{avg} ≤0.5% @ 425 - 700nm
Edges: Seamed
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700
Length (mm): 254.00
Width (mm): 203.20

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant