 



## 25 x 25mm, 0.25mm Spacing, Glass Distortion Target



Stock #58-527 3-5 DAYS

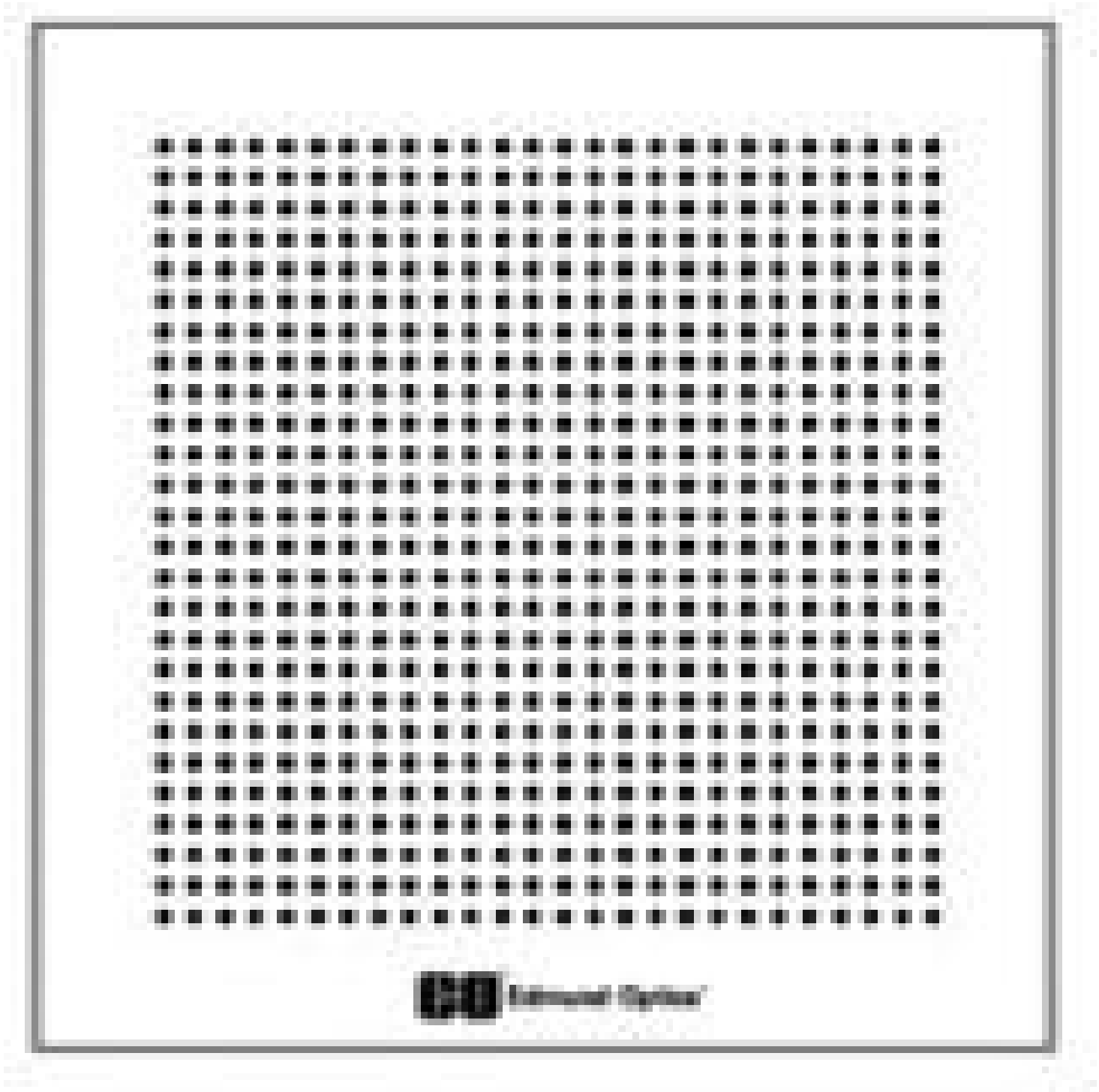

1



S\$904.80

ADD TO CART

Qty 1-4

S\$904.80

Qty 5+

S\$860.43

Volume Pricing

[Request Quote](#)

Get Product Downloads

**Coating:**  
Reflective First Surface Chromium  
R<sub>abs</sub> = 50% ±5% @ 550nm

**Dot Diameter (mm):**  
0.125

**Dot Spacing (mm):**

|                                                                              |
|------------------------------------------------------------------------------|
| 0.250                                                                        |
| <b>Substrate:</b><br>Soda Lime Float Glass                                   |
| <b>Optical Density OD (Average):</b><br>>3.0                                 |
| <b>Overall Accuracy (mm):</b><br>±0.002                                      |
| <b>Pattern Size (mm):</b><br>25 x 25                                         |
| <b>Dimensions (inches):</b><br>2 x 2                                         |
| <b>Surface Quality:</b><br>40-20                                             |
| <b>Thickness (mm):</b><br>1.50                                               |
| <b>Type:</b><br>Chrome on Glass                                              |
| <b>Dot Diameter Tolerance (mm):</b><br>± 0.002                               |
| <b>Dot Spacing Tolerance (mm):</b><br>± 0.002 Center to Center               |
| <b>NIST Certification:</b><br>Serialized NIST Traceable Certificate Included |
| <b>Flatness (inches):</b><br>0.001                                           |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 209:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |