


25 x 25mm, 1.0mm Spacing, Glass Distortion Target

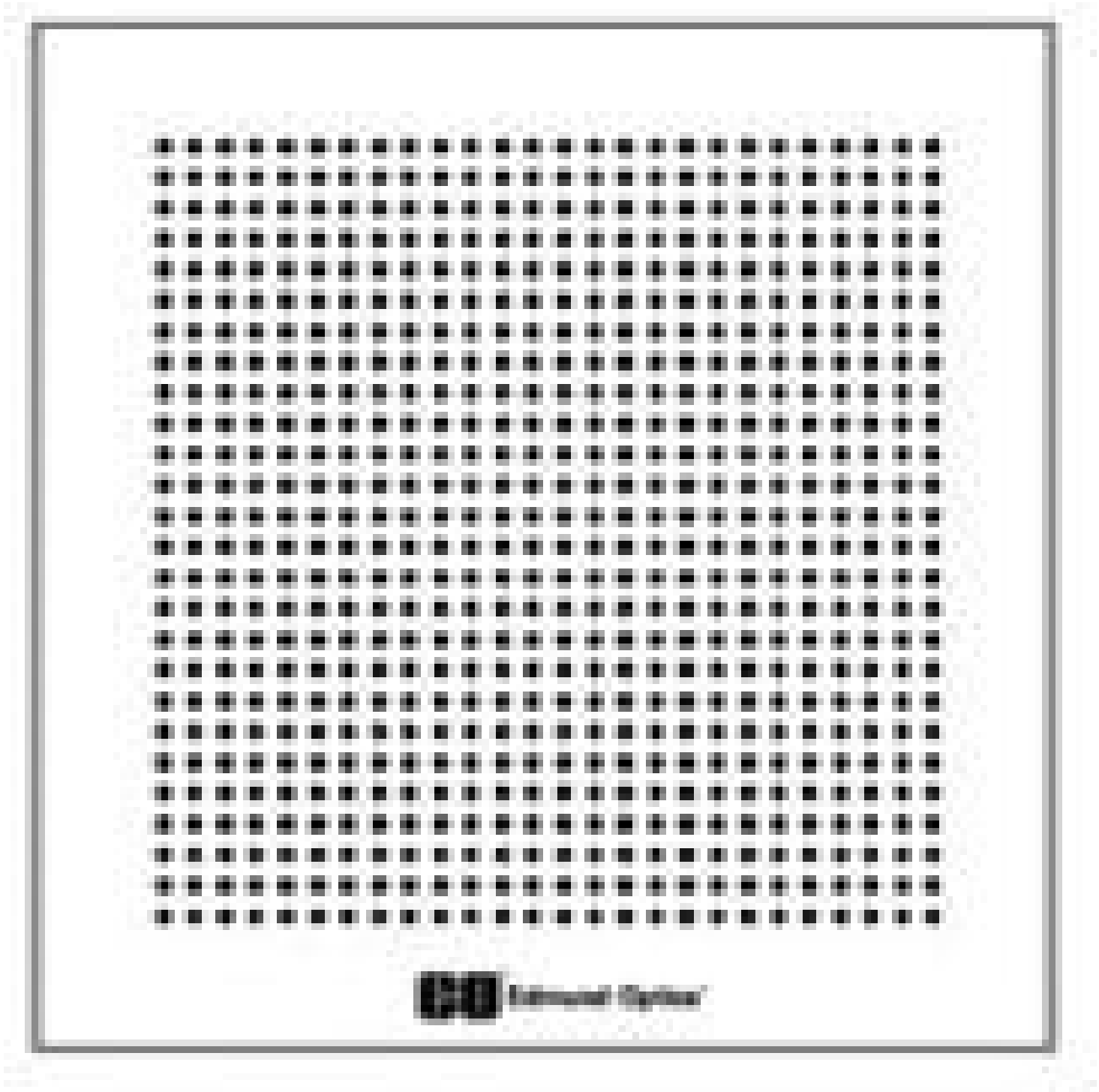

Stock #62-209 3-5 DAYS

- 1 + **\$S\$756.90**

ADD TO CART

Qty 1-4

\$S\$756.90

Qty 5+

\$S\$719.92

Volume Pricing

[Request Quote](#)

Get Product Downloads

Coating:
Reflective First Surface Chromium
R_{abs} = 50% ±5% @ 550nm

Dot Diameter (mm):
0.250

Dot Spacing (mm):

1.000
Substrate: Soda Lime Float Glass
Optical Density OD (Average): >3.0
Overall Accuracy (mm): ±0.002
Pattern Size (mm): 25 x 25
Dimensions (inches): 2 x 2
Surface Quality: 40-20
Thickness (mm): 1.50
Type: Chrome on Glass
Dot Diameter Tolerance (mm): ± 0.002
Dot Spacing Tolerance (mm): ± 0.002 Center to Center
NIST Certification: Serialized NIST Traceable Certificate Included
Flatness (inches): 0.001

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View