


TECHSPEC[®] 25.4mm Dia. VIS, Precision Broadband Laser Mirror

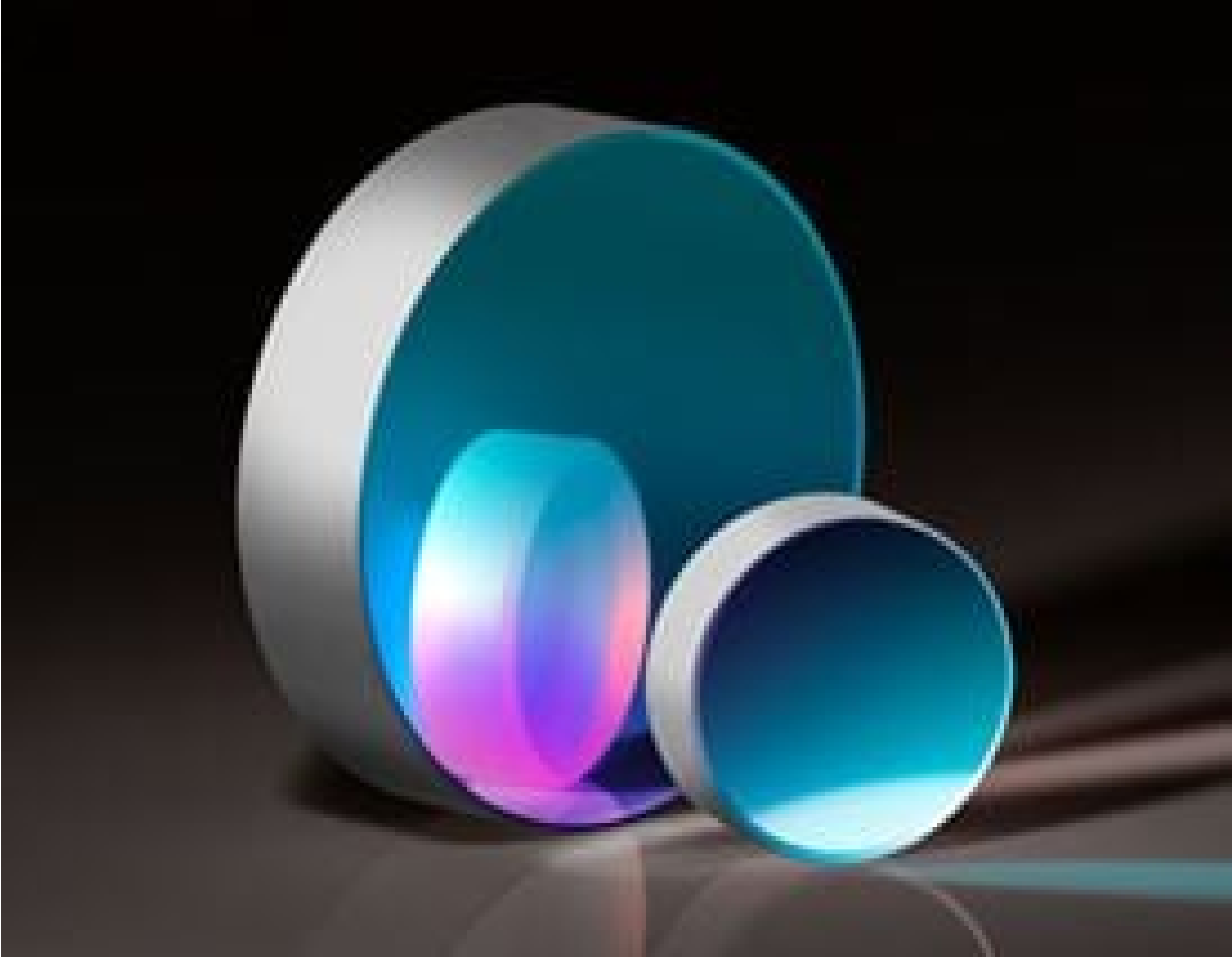

Stock #45-596 3-5 DAYS

-

1

+

S\$226.20

ADD TO CART

Qty 1-5

S\$226.20

Qty 6+

S\$198.65

Volume Pricing

[Request Quote](#)

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Clear Aperture (%):
>80

Durability:

ML-M-13508-C
Back Surface: Ground
Coating Specification: R _{avg} >99% @ 400 - 700nm
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/10
Irregularity (P-V) @ 632.8nm: λ/20
Coating Type: Dielectric
Coating: Dielectric Mirror (400-700nm)
Diameter (mm): 25.40 +0.0/-0.2
Thickness (mm): 8.00 ±0.3
Angle of Incidence (°): 0-45
Substrate: ☐ BOROFLOAT®
Note: Optical Power: λ/10
Damage Threshold, By Design: ☐ 1 J/cm ² @ 10ns

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View