

TECHSPEC<sup>®</sup> 25.4mm Length, M4 Stud, Steel Post



Stock #58-950 CLEARANCE 2 In Stock

-

1

+

S\$15<sup>.31</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1+         | S\$15.31 each                 |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

SPECIFICATIONS

General

Type:

Metric

Note:

Adapter #58-984 is included. Additional [thread adapters](#) available separately.

Physical & Mechanical Properties

|       |                    |
|-------|--------------------|
| 1.0   | Length (inches):   |
| 25.40 | Length (mm):       |
| 0.5   | Diameter (inches): |
| 12.70 | Diameter (mm):     |

Threading & Mounting

|         |              |
|---------|--------------|
| M4 x0.7 | Male Thread: |
|---------|--------------|


Regulatory Compliance

|           |                             |
|-----------|-----------------------------|
| Compliant | RoHS 2015:                  |
| View      | Certificate of Conformance: |
| Compliant | REACH 241:                  |

PRODUCT DETAILS

- Male M4 x0.7 or M6 x1.0 Stud, Female M6 x1.0 Base
  - Posts Include Interchangeable Male Stud and Removable Base S.H.S.S.
  - Available in Variety of Lengths
  - [English Versions Also Available](#)
- TECHSPEC® Metric Stainless Steel Mounting Posts include a 6.35mm long male thread stud adapter that is easily interchangeable with other adapters to ensure compatibility between these posts and any optical mount. Removing the included adapter reveals female M4 threads on the post. Each optical post also has a thru-hole to allow an Allen wrench or other tool to rotate the post easily. Thread values are laser engraved on each post for quick identification and integration. TECHSPEC Metric Stainless Steel Mounting Posts are offered in a variety of lengths. [English versions are also available for purchase.](#)

TECHNICAL INFORMATION

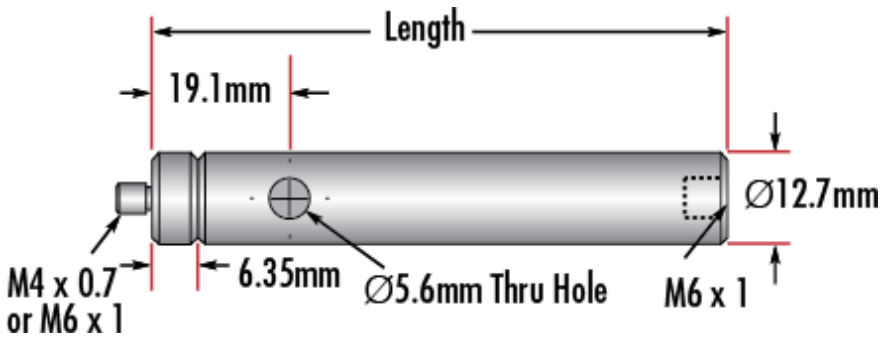

| #68-231   |                            |     |
|-----------|----------------------------|-----|
| Stock No. | Description                | Qty |
| #58-950   | Steel Post, 25.4mm Length  | 1   |
| #58-951   | Steel Post, 38.1mm Length  | 1   |
| #58-952   | Steel Post, 50.8mm Length  | 2   |
| #58-954   | Steel Post, 76.2mm Length  | 2   |
| #58-955   | Steel Post, 101.6mm Length | 2   |
| #58-956   | Steel Post, 152.4mm Length | 1   |
| #58-957   | Steel Post, 203.2mm Length | 1   |

| #68-232   |                            |     |
|-----------|----------------------------|-----|
| Stock No. | Description                | Qty |
| #59-757   | Steel Post, 25.4mm Length  | 1   |
| #59-758   | Steel Post, 38.1mm Length  | 1   |
| #59-759   | Steel Post, 50.8mm Length  | 2   |
| #59-761   | Steel Post, 76.2mm Length  | 2   |
| #59-762   | Steel Post, 101.6mm Length | 2   |
| #59-763   | Steel Post, 152.4mm Length | 1   |
| #59-764   | Steel Post, 203.2mm Length | 1   |