

TECHSPEC<sup>®</sup> 25mm Dia., 0.40mm Thick, Uncoated, Gorilla Glass<sup>®</sup> Window



Gorilla<sup>®</sup> Glass Windows



Stock #21-232 20+ In Stock

-

1

+

S\$48<sup>-30</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-5        | S\$48.30 each                 |
| Qty 6-25       | S\$39.20 each                 |
| Qty 26-99      | S\$35.00 each                 |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

General

|                                       |                   |
|---------------------------------------|-------------------|
| Type:                                 | Protective Window |
| Chemical Strengthening Cycle (hours): | 8                 |

Physical & Mechanical Properties

|                      |                         |
|----------------------|-------------------------|
| 22.50                | Clear Aperture CA (mm): |
| 25.00 ±0.25          | Diameter (mm):          |
| 0.40 ±0.05           | Thickness (mm):         |
| Protective as needed | Bevel:                  |
| 90.00                | Clear Aperture (%):     |
| Fine Ground          | Edges:                  |
| 0.22                 | Poisson's Ratio:        |
| 70                   | Young's Modulus (GPa):  |

Optical Properties

|                |                                        |
|----------------|----------------------------------------|
| Uncoated       | Coating:                               |
| Gorilla® Glass | Substrate: <input type="checkbox"/>    |
| 1.5            | Index of Refraction (n <sub>d</sub> ): |
| 80-50          | Surface Quality:                       |
| 350 - 2200     | Wavelength Range (nm):                 |

Material Properties

|                    |                                                              |
|--------------------|--------------------------------------------------------------|
| 2.39               | Density (g/cm³):                                             |
| 7.58 (0 to +300°C) | Coefficient of Thermal Expansion CTE (10 <sup>-6</sup> /°C): |

Regulatory Compliance


|           |                             |
|-----------|-----------------------------|
| Compliant | RoHS 2015:                  |
| View      | Certificate of Conformance: |
| Compliant | Reach 247:                  |

## Product Details

- Chemically Strengthened Drawn Glass
- Highly Resistance to Surface Scratches
- Ideal for Electronic Displays

Gorilla® Glass Windows are chemically strengthened to reduce the propagation of surface flaws. These thin windows feature superior surface quality and excellent scratch resistance. With greater than 90% transmission from 350 - 600nm, these windows are excellent protective covers for electronic displays in consumer and industrial applications. Gorilla® Glass Wndows are widely used as protective cover glass for high-end display devices such as laptops, televisions and mobile phones. Due to their durable construction, they are ideal for even the most demanding applications.

## Technical Information

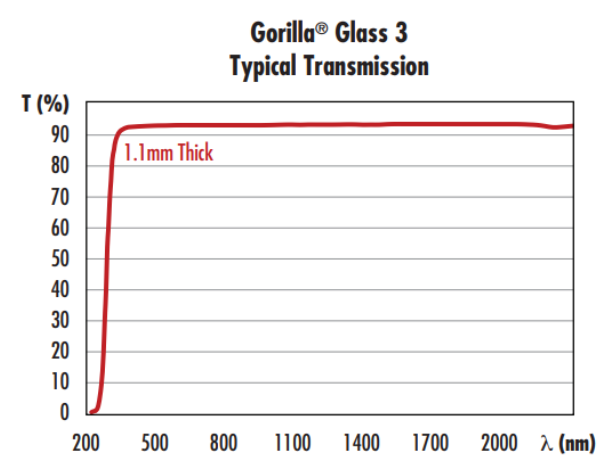

## Custom

Edmund Optics offers comprehensive custom manufacturing services for optical and imaging components tailored to your specific application requirements. Whether in the prototyping phase or preparing for full-scale production, we

provide flexible solutions to meet your needs. Our experienced engineers are here to assist—from concept to completion.

Our capabilities include:

- Custom dimensions, materials, coatings, and more
- High-precision surface quality and flatness
- Tight tolerances and complex geometries
- Scalable production—from prototype to volume

Learn more about our [custom manufacturing capabilities](#) or submit an inquiry [here](#).

## Quote Your Size

## Compatible Mounts

;