


25mm Dia x -103.36mm FL Enhanced Aluminum Coated, Convex Mirror

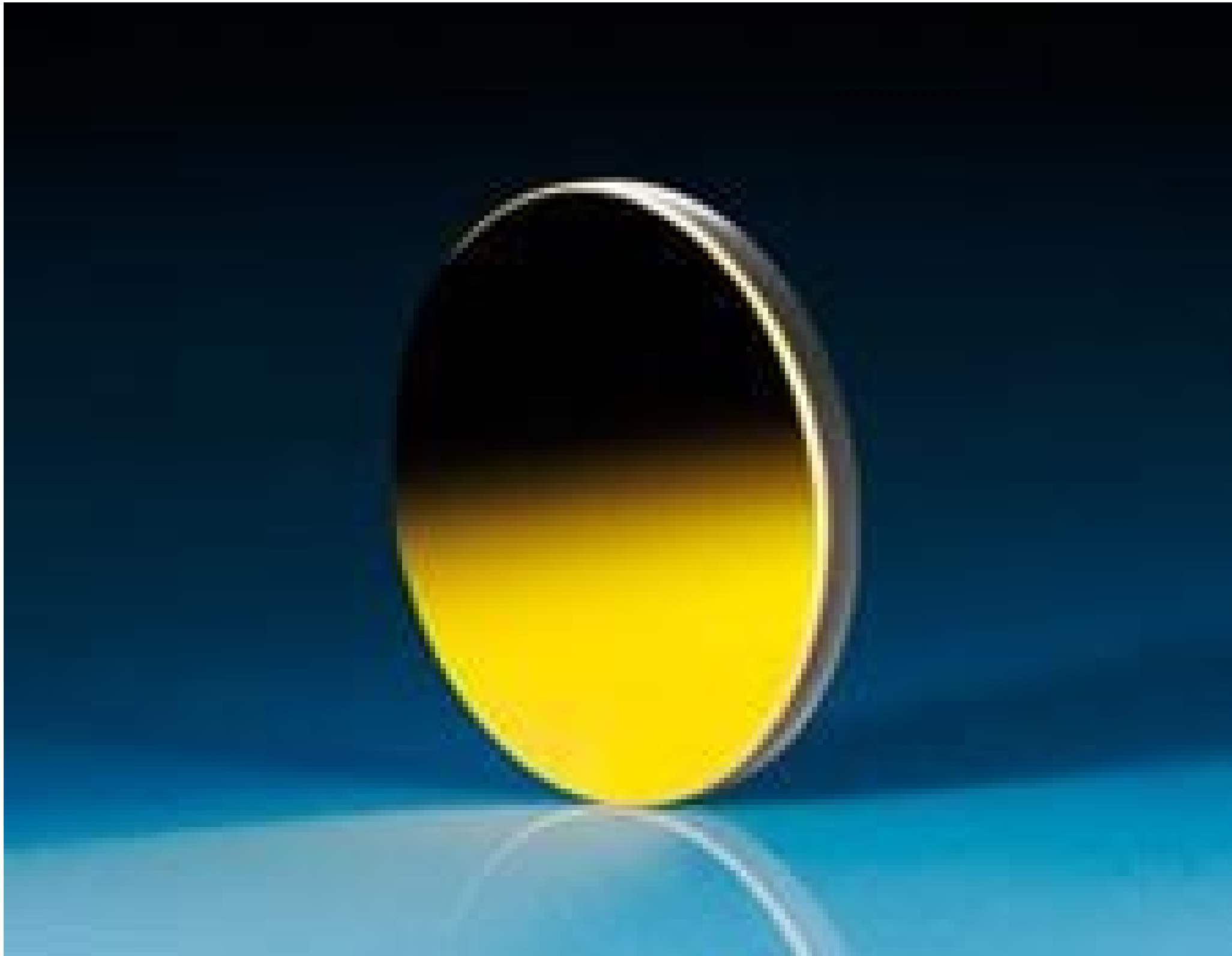

Stock **#64-064** 3-5 DAYS

- 1 +

S\$65.97

ADD TO CART

Qty 1-5

S\$65.97

Qty 6+

S\$59.45

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
25.00 +0.00/-0.10

Focal Length FL (mm):
-104.60

Center Thickness CT (mm):
3.20

Clear Aperture (%):
90

Coating: Enhanced Aluminum (450-650nm)
Coating Specification: R _{avg} >95% @450 - 650nm
Coating Type: Metal
Edge Thickness ET (mm): 2.83
Focal Length Tolerance (%): ±2
Radius R (mm): 209.20
Substrate: N-K5
Surface Quality: 60-40
Type: Spherical Mirror
Wavelength Range (nm): 450 - 650
Damage Threshold, Reference: 0.2 J/cm² @532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant