


## 26mm Diameter, English Hole Gauge, Contact Reticle

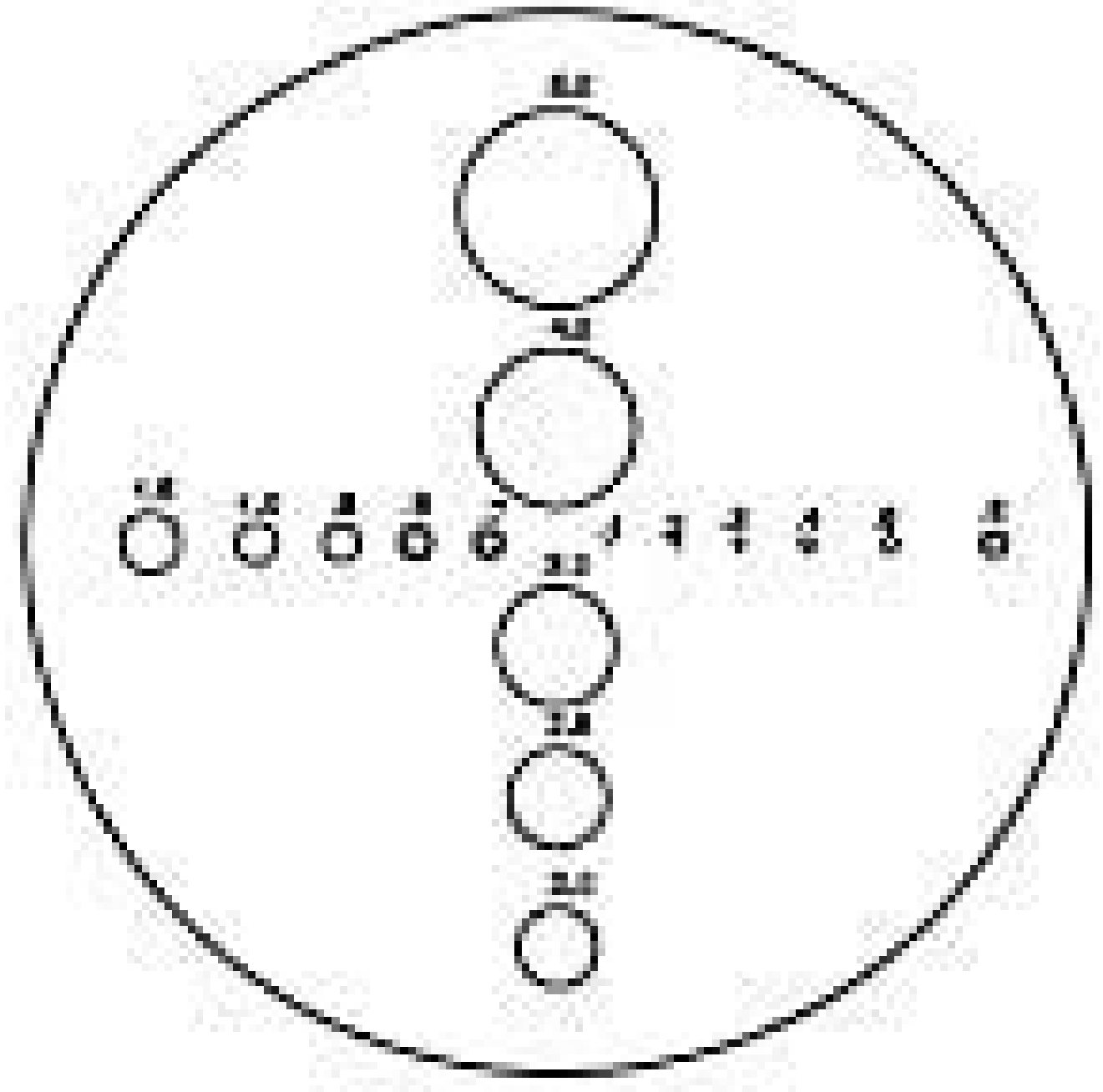

Hole Guage

Stock #64-853 3-5 DAYS



1



S\$97.15

ADD TO CART

Qty 1-4

S\$97.15

Qty 5+

S\$91.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):

26.00 ±0.125

Angle Tolerance (arcsec):

±1

Line Thickness (µm):

25.00

Surface Quality:

|                                              |
|----------------------------------------------|
| 60-40                                        |
| <b>Thickness (mm):</b><br>1.50               |
| <b>Thickness Tolerance (mm):</b><br>±0.10    |
| <b>Type:</b><br>English Hole Gauge           |
| <b>Line to Line Accuracy (µm):</b><br>±2     |
| <b>Bevel:</b><br>Protective bevel as needed  |
| <b>Parallelism (arcsec):</b><br><30          |
| <b>Centering (mm):</b><br>0.25               |
| <b>Line Thickness Tolerance (µm):</b><br>±13 |
| <b>Surface Flatness (P-V):</b><br>3 - 4λ     |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 209:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |