


27mm Diameter, Metric Hole Gauge, Contact Reticle

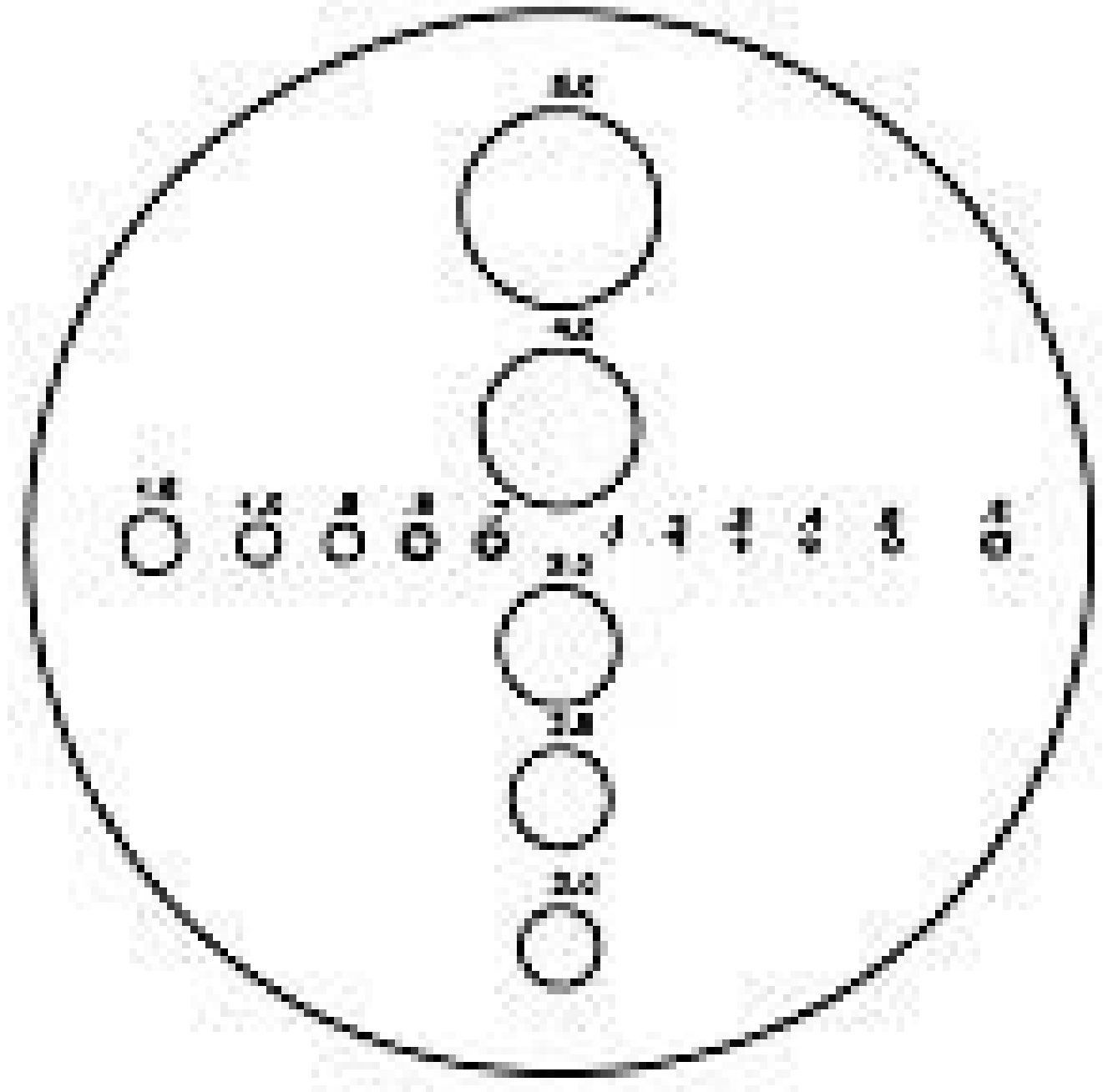

Hole Guage

Stock **#39-457** 3-5 DAYS



1



S\$97.15

ADD TO CART

Qty 1-4

S\$97.15

Qty 5+

S\$91.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):

27.00 ±0.05

Angle Tolerance (arcsec):

±1

Line Thickness (µm):

25.00

Surface Quality:

60-40
Thickness (mm): 2.28
Thickness Tolerance (mm): ±0.127
Type: Metric Hole Gauge
Line to Line Accuracy (µm): ±2
Bevel: Protective bevel as needed
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View