


2" x 2", Line Grid Low Reflective Chrome

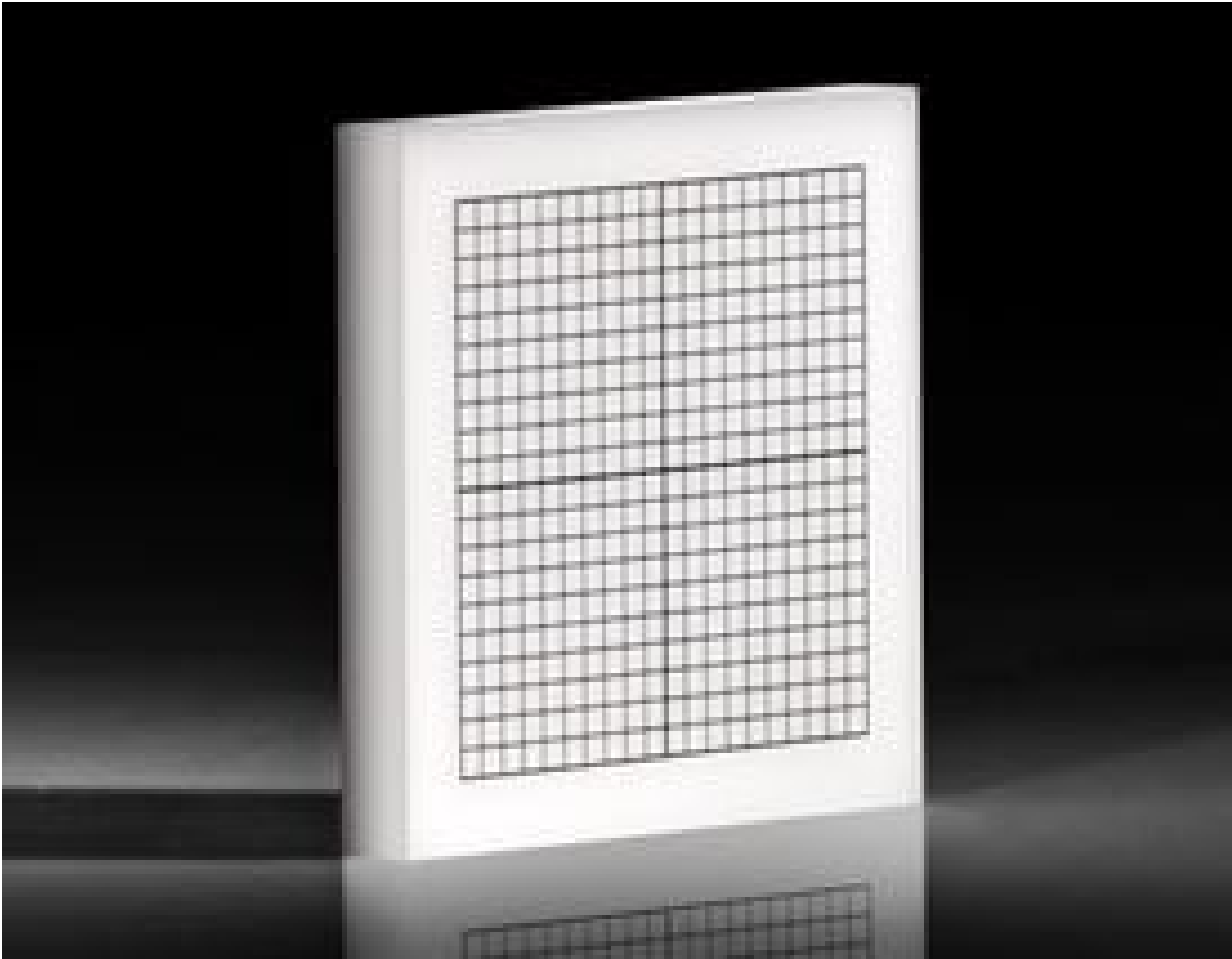

Line Grid Low Reflective Chrome

Stock **#62-538** 3-5 DAYS



1



S\$1,067.20

ADD TO CART

Qty 1-4
S\$1,067.20
Qty 5+
S\$1,013.98
Volume Pricing
Request Quote

Get Product Downloads

Substrate:
White Soda Lime Glass

Length (mm):
50.80

Optical Density OD (Average):
>3.0

Overall Accuracy (mm):

±0.002
Pattern Size (mm): 30.1 x 30.1
Surface Quality: 20-10 over active area, 60-40 outside
Thickness (mm): 2.50
Width (mm): 50.80
Line Thickness (mm): Center Line: 0.1 ±0.002 Inner Line: 0.075 ±0.002
Center to Center Spacing (mm): 1.00 ±0.001
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View