

TECHSPEC 40mm, Center Drive, Standard Top, English Extended Micrometer



Stock **#66-404** **5 In Stock**

⊖ 1 ⊕ **\$644.00**

ADD TO CART

Volume Pricing	
Qty 1-2	\$644.00 each
Qty 3+	\$562.24 each
Need More?	Request Quote

Product Downloads

General

English **Type:**


Physical & Mechanical Properties

Linear (X) **Type of Movement:**


Crossed Roller Bearing **Guide System:**

Center Drive **Drive Orientation:**


30mm Standard-Top Stages - Center Drive

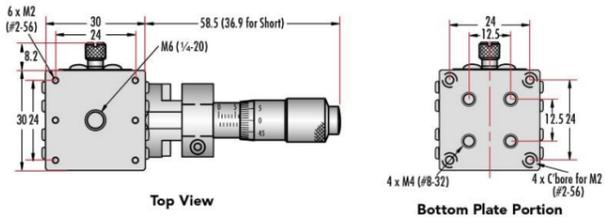


30mm Standard-Top Stages - Side Drive

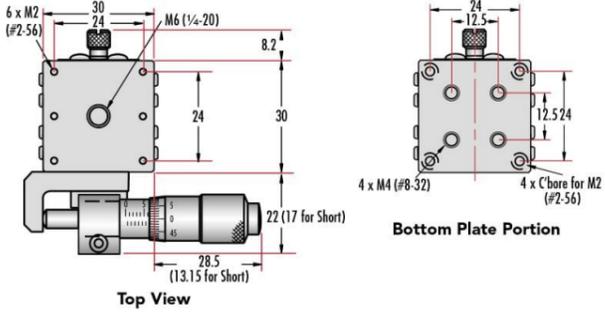


40mm Standard-Top Stages - Center Drive

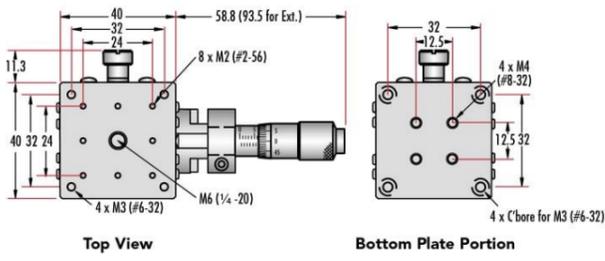


40mm Standard-Top Stages - Side Drive

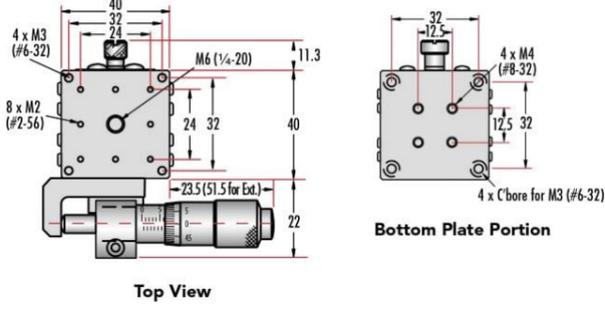


70mm Standard-Top Stages - Center Drive

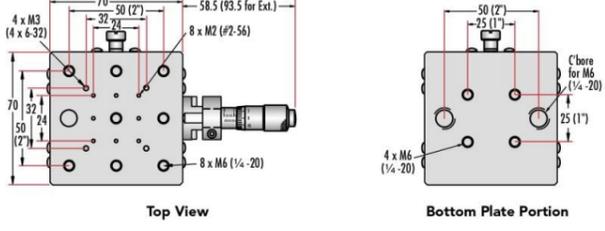

70mm Standard-Top Stages - Side Drive

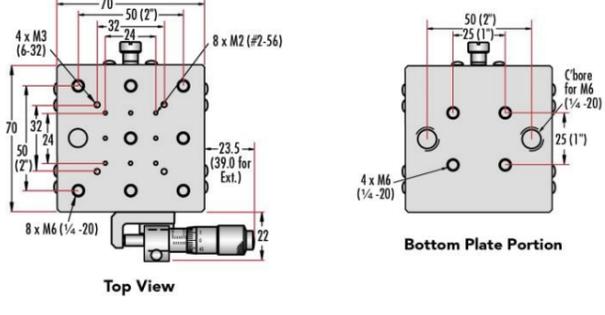

125mm Standard-Top Stages - Center Drive

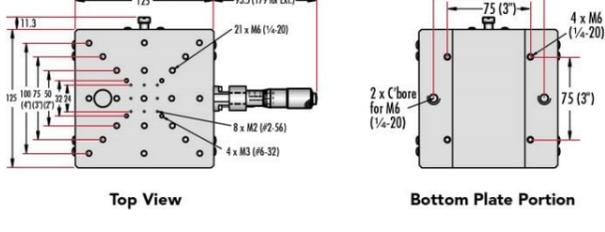

125mm Standard-Top Stages - Side Drive

