


TECHSPEC®

4.0mm Diameter x 5.0mm Length, N-BK7 Drum Lens

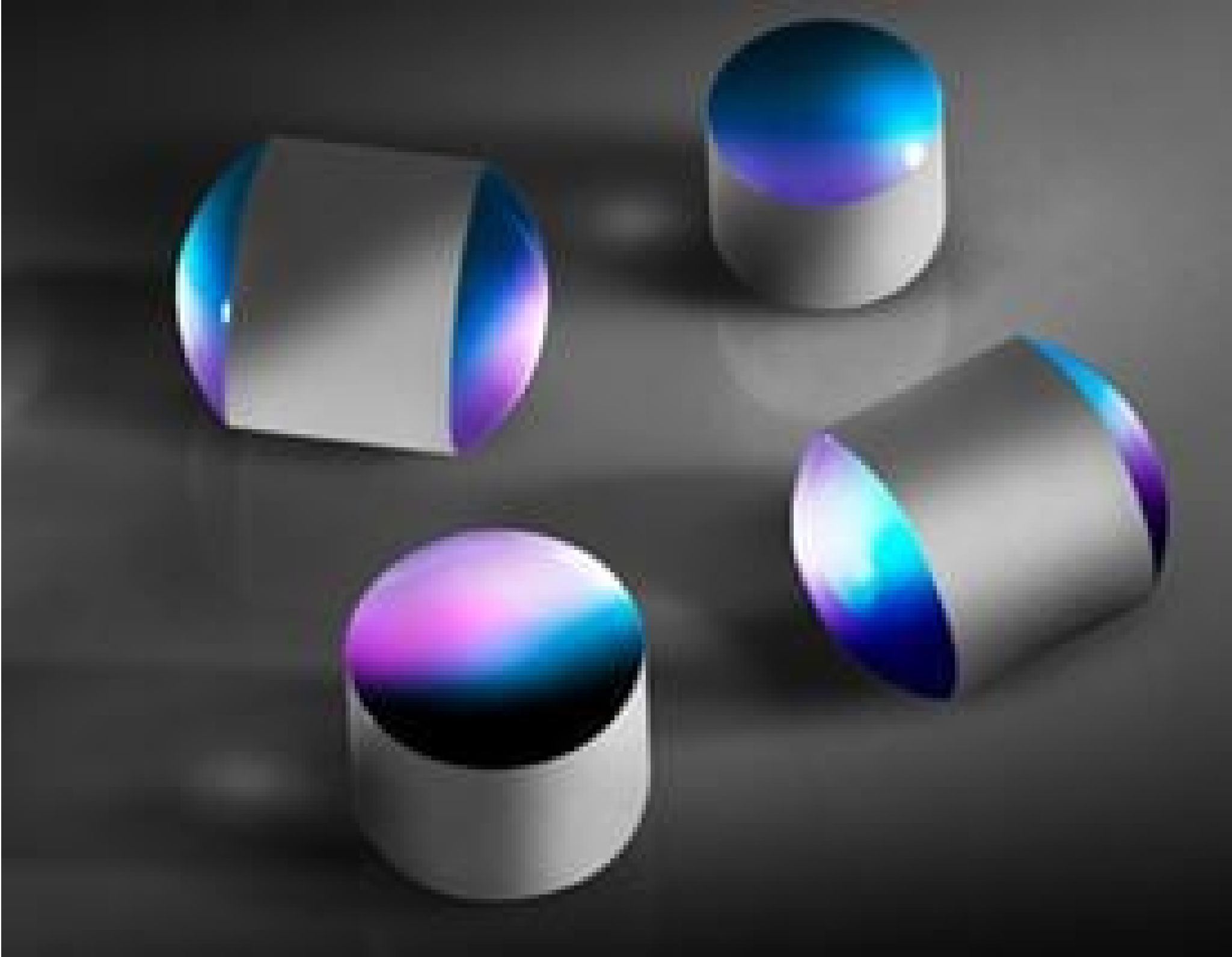

Stock #45-551

CLEARANCE

3-5 DAYS

-

1

+

S\$28.93

ADD TO CART

Qty 1+

S\$28.93

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):

4.00

Substrate: ☐

N-BK7

Coating:

Uncoated

Type:

Drum Lens

Wavelength Range (nm):

350 - 2200

Index of Refraction n_d: 1.517
Length (mm): 5.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.50
Radius Tolerance (μm): +0/-1.5
Surface Quality: 40-20
Diameter Tolerance (μm): +0/-50

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View