 



[All Products](#) / [Test Targets](#) / [Distortion Test Targets](#) / [Fixed Frequency Grid Distortion Targets](#)

[See all 26 Products in Family](#)

50 x 50mm, 0.500mm Spacing, White Ivory Distortion Target

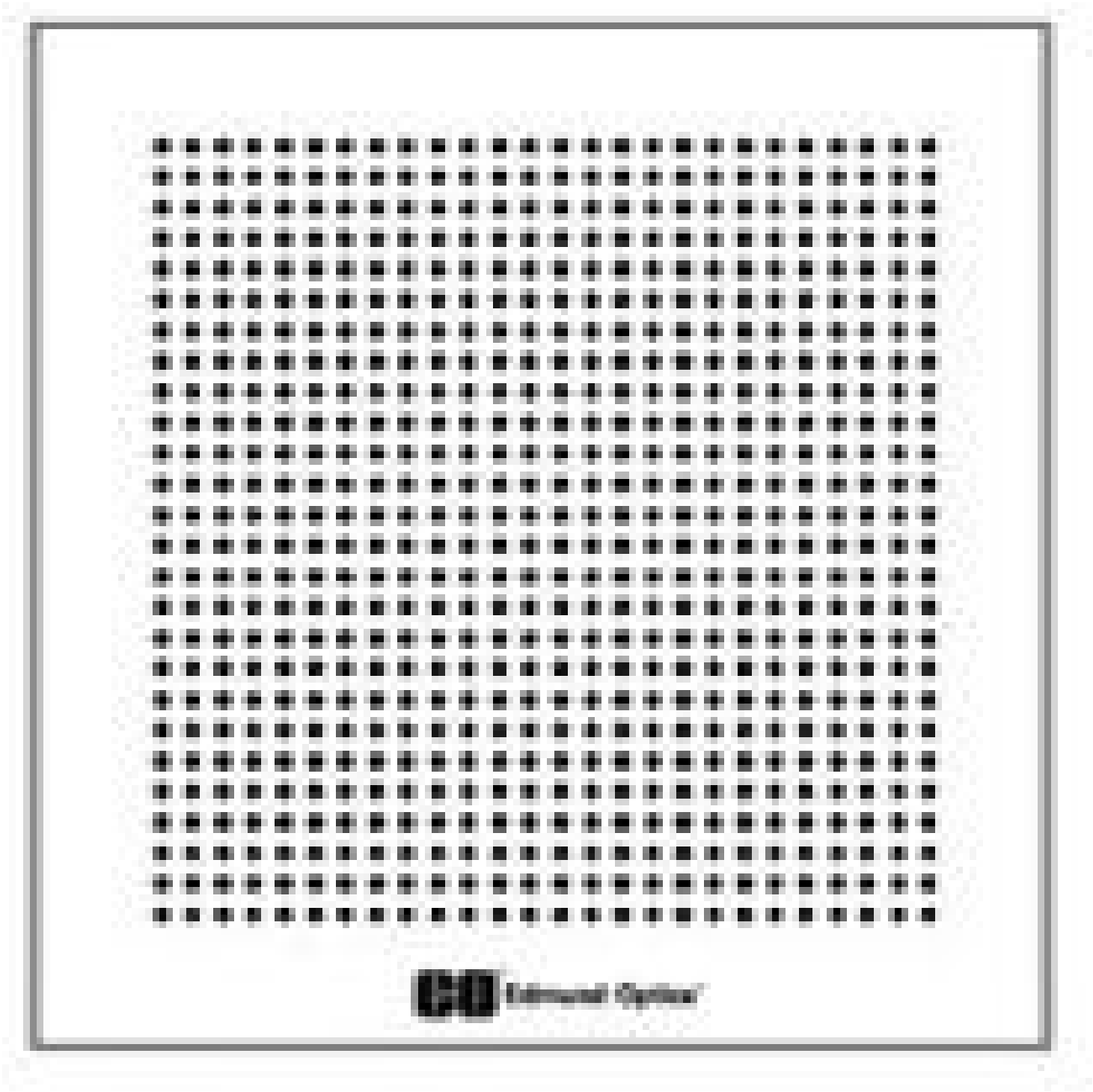

Stock **#63-986** [CONTACT US](#)



1



S\$1,270.20

ADD TO CART

Qty 1-4
S\$1,270.20
Qty 5+
S\$1,208.14
Volume Pricing
Request Quote

Get Product Downloads

Coating:
Reflective First Surface Chromium
R_{abs} = 50% ±5% @ 550nm

Dot Diameter (mm):
0.250

Dot Spacing (mm):

0.500
Substrate: White Ivory Soda Lime Glass
Optical Density OD (Average): >3.0
Overall Accuracy (mm): ±0.002
Pattern Size (mm): 50 x 50
Dimensions (inches): 3 x 3
Surface Quality: 40-20
Thickness (mm): 3.20
Type: Chrome on White Ivory Glass
Dot Diameter Tolerance (mm): ± 0.002
Dot Spacing Tolerance (mm): ± 0.002 Center to Center
NIST Certification: Serialized NIST Traceable Certificate Included
Flatness (inches): 0.001

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
