


5mW, 635nm Laser Bat Power ZAT, 60° X-Hair

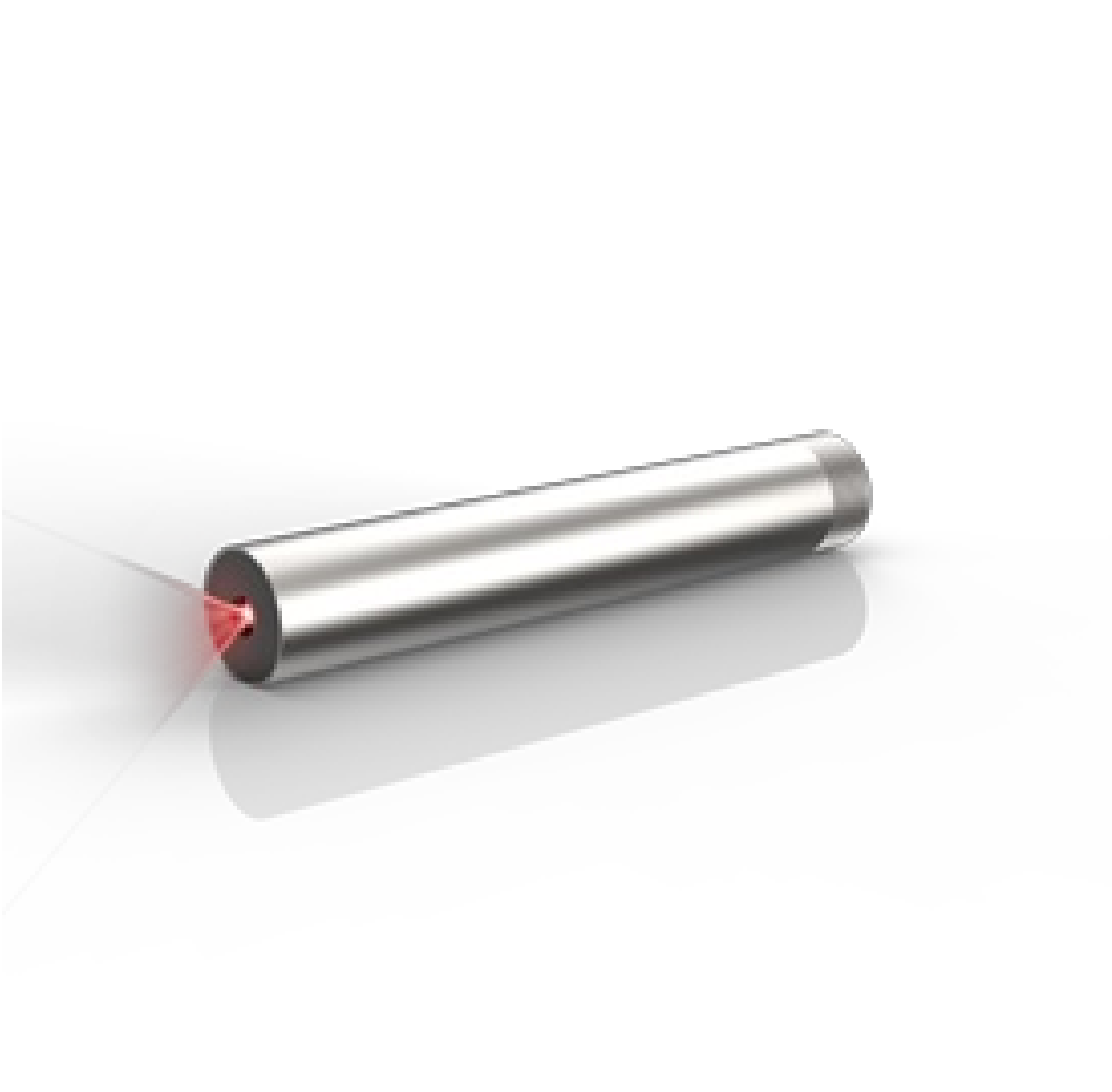

Stock **#19-540** [CONTACT US](#)

-

1

+

S\$435.00

ADD TO CART

Qty 1-9
S\$435.00

Qty 10+
S\$391.50

Volume Pricing

Get Product Downloads



Output Power (mW):
5

Wavelength (nm):
635.00

Weight (g):
162

Power Requirement:
1 AA Battery (Not Included)

Style:
Crosshair

Output Type:
Free Space

Laser Class - CDRH:
1M

Color:
Red

Fan Angle (°):
60.00

Focus Range:
Up to 1,500mm

Length (mm):
124.00

Environmental Rating:
IP40

Regulatory Compliance

RoHS:
[Compliant](#)

Certificate of Conformance:
[View](#)