

60 x 35mm Metric Base Plate



Stock #58-995 20+ In Stock

-

1

+

S\$43^{.05}

ADD TO CART

Volume Pricing	
Qty 1+	S\$43.05 each
Need More?	Request Quote

Product Downloads

SPECIFICATIONS

General	
	Type:
Metric	
Physical & Mechanical Properties	
	Length (mm):
60.00	

35.00	Width (mm):
7.00	Thickness (mm):
Black Anodized Aluminum	Construction:
2	Number of Slots:

Threading & Mounting

(4) M4 x0.7, (5) M6 x1.0	Mounting Threads:
--------------------------	-------------------


Regulatory Compliance

Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 250:

PRODUCT DETAILS

- Two Size Options
 - Two Platform Options: English or Metric
 - English: Four #8-32 holes on ½" Square and Four ¼-20 Holes on 1" Square
 - Metric: Four M4 x0.7 holes on 12.5mm Square and Four M6 x 1 Holes on 25mm Square
 - Anodized Aluminum Construction
- Base Plates have Metric or English threaded holes and additional center trapped hole (M6 x 1 or ¼-20). Base Plates also have extended center slots that ensure full use on matching metric or English breadboard patterns. 85mm x50mm Base Plates have same tapped holes and slots as 60mm x35mm Base Plates, but with extra short slots for added flexibility.

TECHNICAL INFORMATION

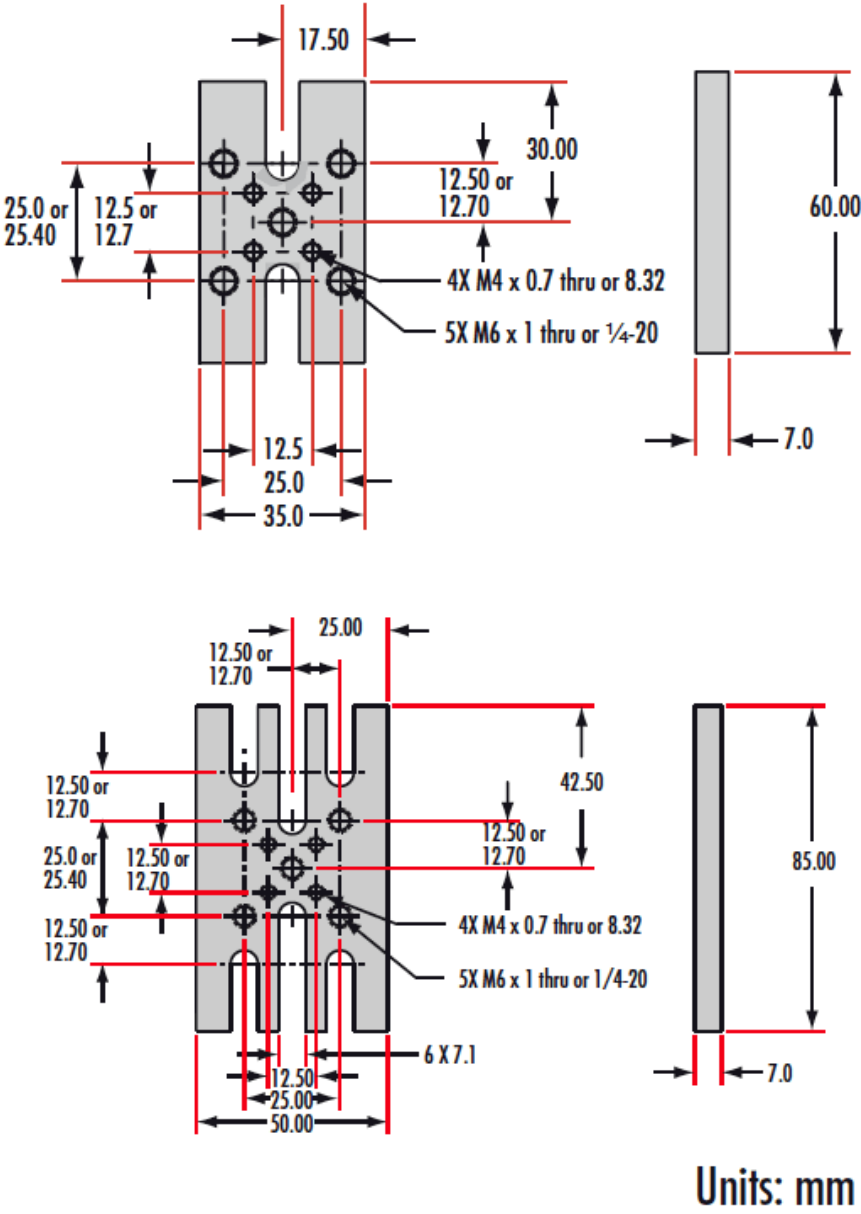

Units: mm