


64 x 97mm Laser Diode Mirror

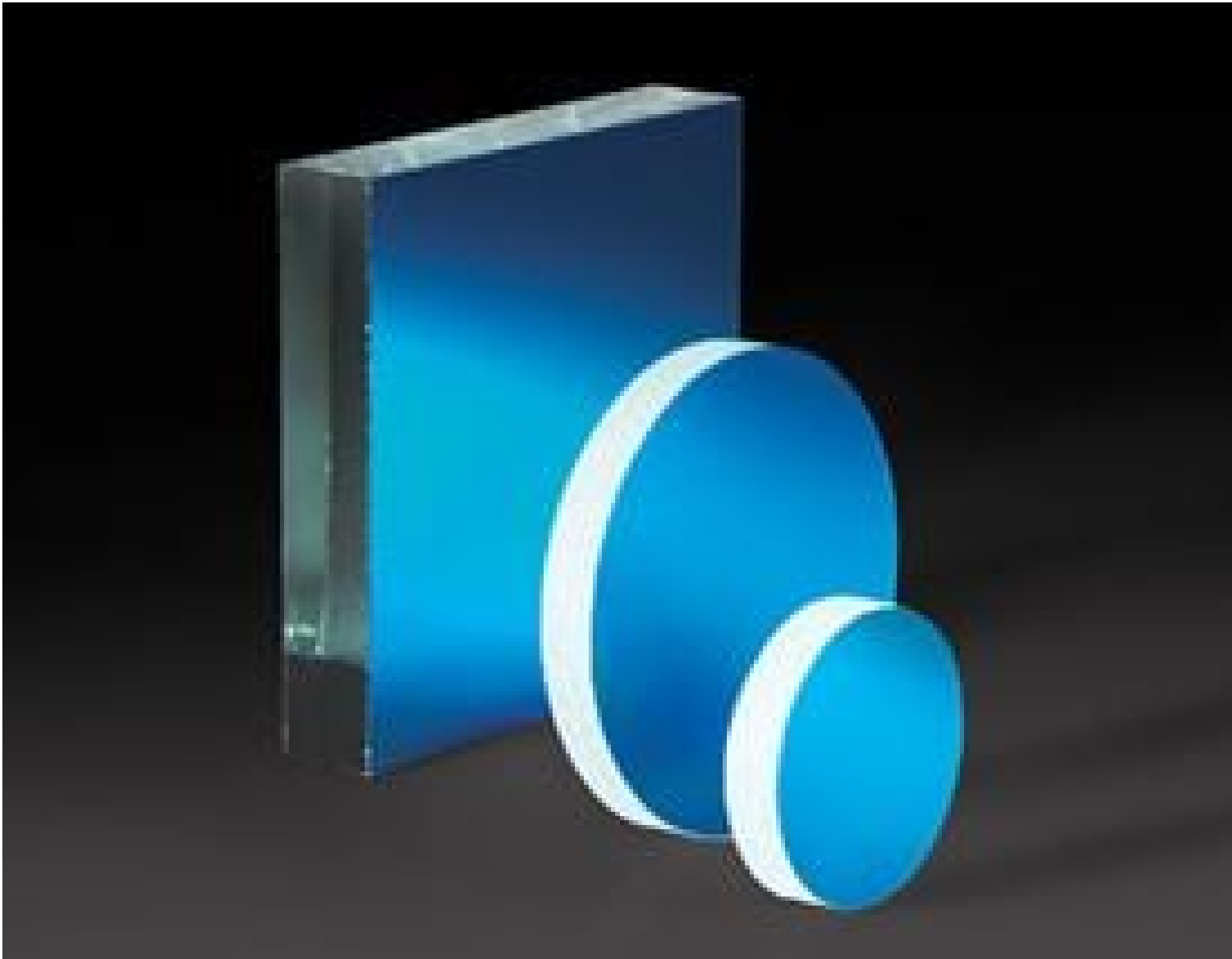

Stock #31-497 3-5 DAYS

- 1 +

S\$65.97

ADD TO CART

Qty 1-10

S\$65.97

Qty 11+

S\$52.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Substrate: ☐ Float Glass

Surface Quality:
80-50

Dimensions (mm):
64.0 x 97.0

Dimensional Tolerance (mm):
±0.25

Coating Specification: R _{abs} >97% @ 633nm
Coating: Dielectric Mirror (500-700nm)
Coating Type: Dielectric
Design Wavelength DWL (nm): 633
Durability: ML-C-48497A
Thickness (mm): 6.35
Type: Flat Mirror
Length (mm): 97.00
Width (mm): 64.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant
