


TECHSPEC[®] 76.2mm Dia. $\lambda/10$ ZERODUR[®] Optical Flat

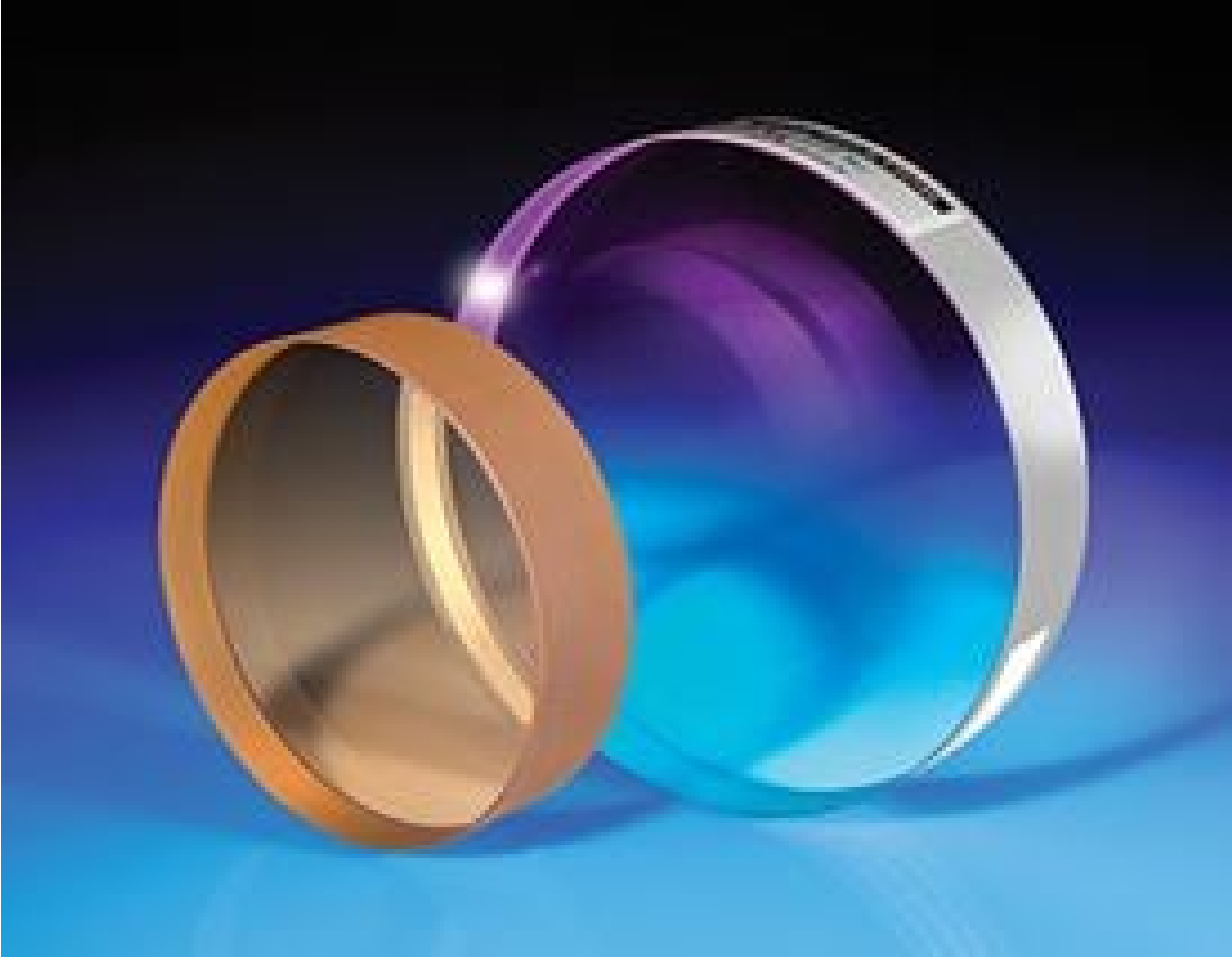

Stock #31-391-000 3-5 DAYS

-

1

+

S\$822.15

ADD TO CART

Qty 1-10

S\$822.15

Qty 11+

S\$739.50

Volume Pricing

[Request Quote](#)

Get Product Downloads

Surface Flatness (P-V):
 $\lambda/10$

Abbe Number (v_d):
56.2

Coating:
Uncoated

Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 0.1
Diameter (mm): 76.20 +0.00/-1.00
Thickness (mm): 19.05 ±1.5
Diameter (inches): 3.00 +0.00/-0.04
Thickness (inches): 0.75 ±0.06
Clear Aperture CA (mm): 68.60
Color: Yellow Tint
Construction: Single Surface
Density (g/cm³): 2.53
Index of Refraction n_d: 1.542
Knoop Hardness (kg/mm²): 620
Parallelism (arcmin): ≤3
Poisson's Ratio: 0.24
Substrate: ZERODUR®
Surface Quality: 60-40
Type: Interferometry Window
Young's Modulus (GPa): 90.3
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View