

## 85 x 50mm English Base Plate



Stock #58-998 **20+ In Stock**

- 1 + S\$48<sup>.30</sup>

**ADD TO CART**

### Volume Pricing

Qty 1+	S\$48.30 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

### General

English **Type:**

### Physical & Mechanical Properties

85.00 **Length (mm):**

50.00 **Width (mm):**

7.00 **Thickness (mm):**

**Construction:**

6 Number of Slots:

### Threading & Mounting

(4) 8-32, (5) 1/4-20 Mounting Threads:

### Regulatory Compliance

Compliant RoHS 2015:

View Certificate of Conformance:



Compliant Reach 250:

## Product Details

- Two Size Options
- Two Platform Options: English or Metric
- English: Four #8-32 holes on 1/2" Square and Four 1/4-20 Holes on 1" Square
- Metric: Four M4 x 0.7 holes on 12.5mm Square and Four M6 x 1 Holes on 25mm Square
- Anodized Aluminum Construction

Base Plates have Metric or English threaded holes and additional center trapped hole (M6 x 1 or 1/4-20). Base Plates also have extended center slots that ensure full use on matching metric or English breadboard patterns. 85mm x 50mm Base Plates have same tapped holes and slots as 60mm x 35mm Base Plates, but with extra short slots for added flexibility.

## Technical Information

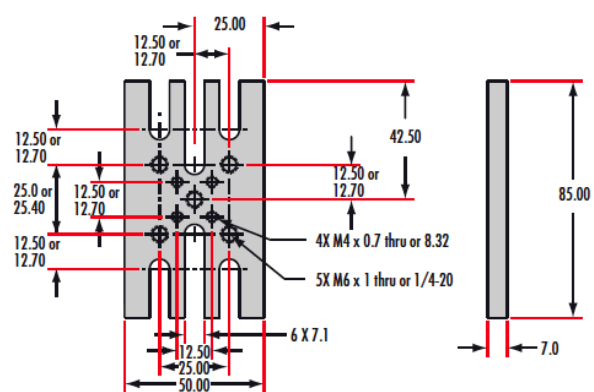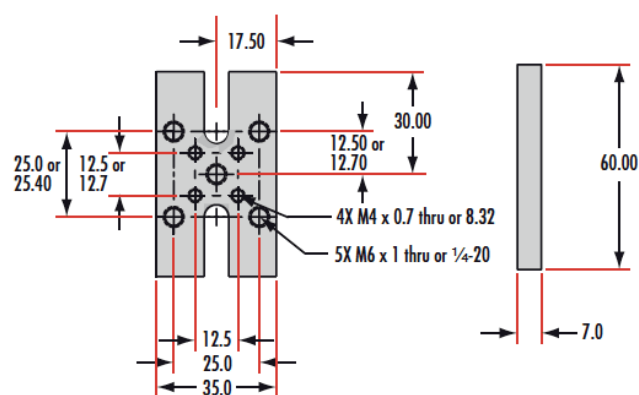

Units: mm