 



# Hoya B410 (UV-VIS) 50.8mm Square Colored Glass Bandpass Filter

See More by [Hoya](#)

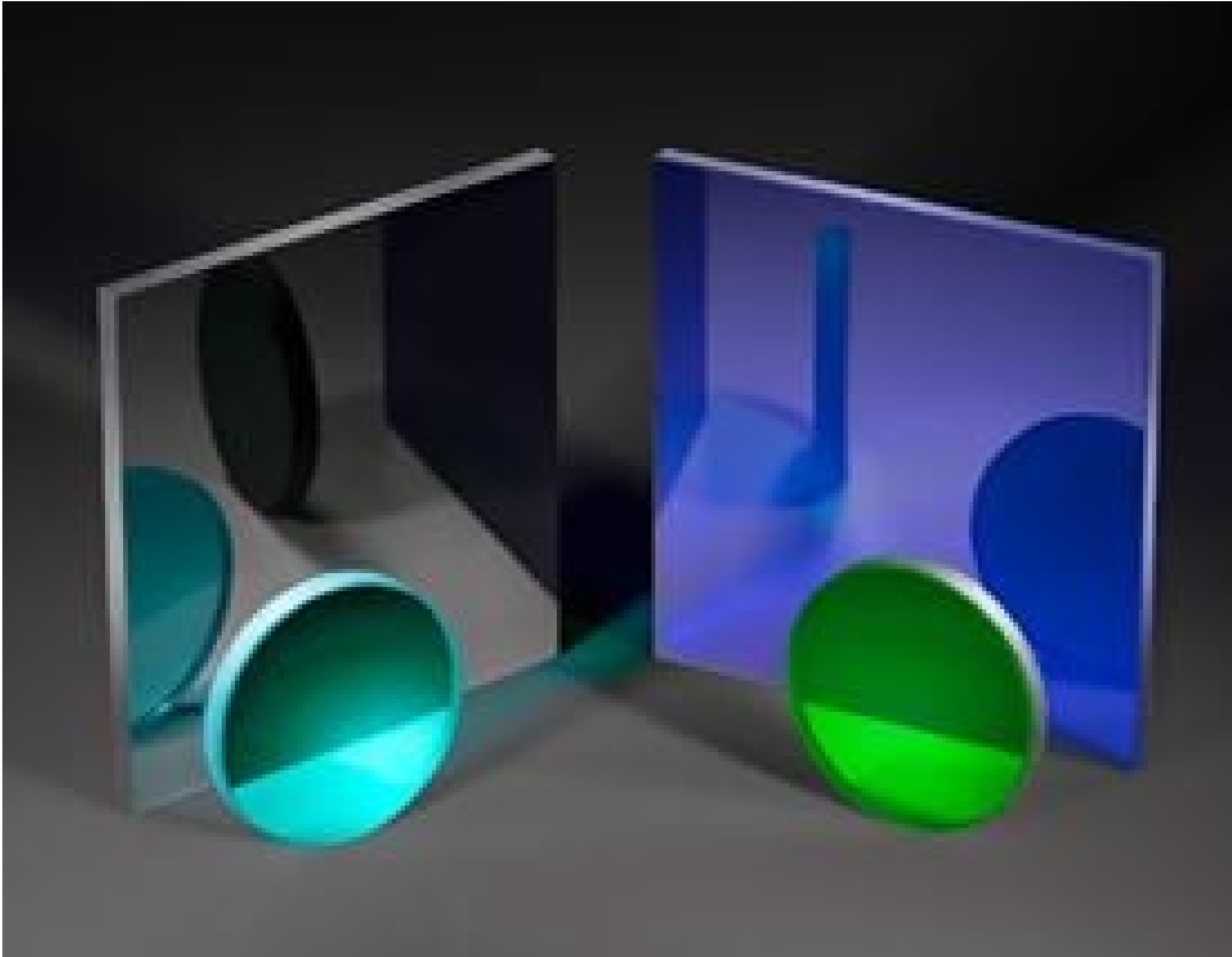

Stock **#34-434** 3-5 DAYS

- 1 + **S\$156.60**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| S\$156.60                     |
| Qty 11+                       |
| S\$139.20                     |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads



**Dimensions (mm):**  
50.8 x 50.8

**Center Wavelength CWL (nm):**  
410.00

|                                                      |
|------------------------------------------------------|
| Density (g/cm³):<br>2.27                             |
| Full Width-Half Max FWHM (nm):<br>232.00             |
| Glass/Filter Number:<br><a href="#">Hoya B410</a>    |
| Substrate: <input type="checkbox"/><br>Colored Glass |
| Length (mm):<br>50.80                                |
| Coating:<br>Uncoated                                 |
| Color:<br>Blue                                       |
| Surface Quality:<br>80-50                            |
| Thickness (mm):<br>2.50                              |
| Thickness Tolerance (mm):<br>±0.2                    |
| Type:<br>Bandpass Filter                             |
| Wavelength:<br>UV-VIS                                |
| Width (mm):<br>50.80                                 |
| Parallelism (arcmin):<br>≤2                          |
| Dimensional Tolerance (mm):<br>+0/-0.25              |

### Regulatory Compliance

|                                                     |
|-----------------------------------------------------|
| RoHS 2015:<br><a href="#">Exempt</a>                |
| Reach 224:<br><a href="#">Compliant</a>             |
| Certificate of Conformance:<br><a href="#">View</a> |