


OD 0.04 - 1.0, 50.8 x 25.4mm Stepped ND Filter

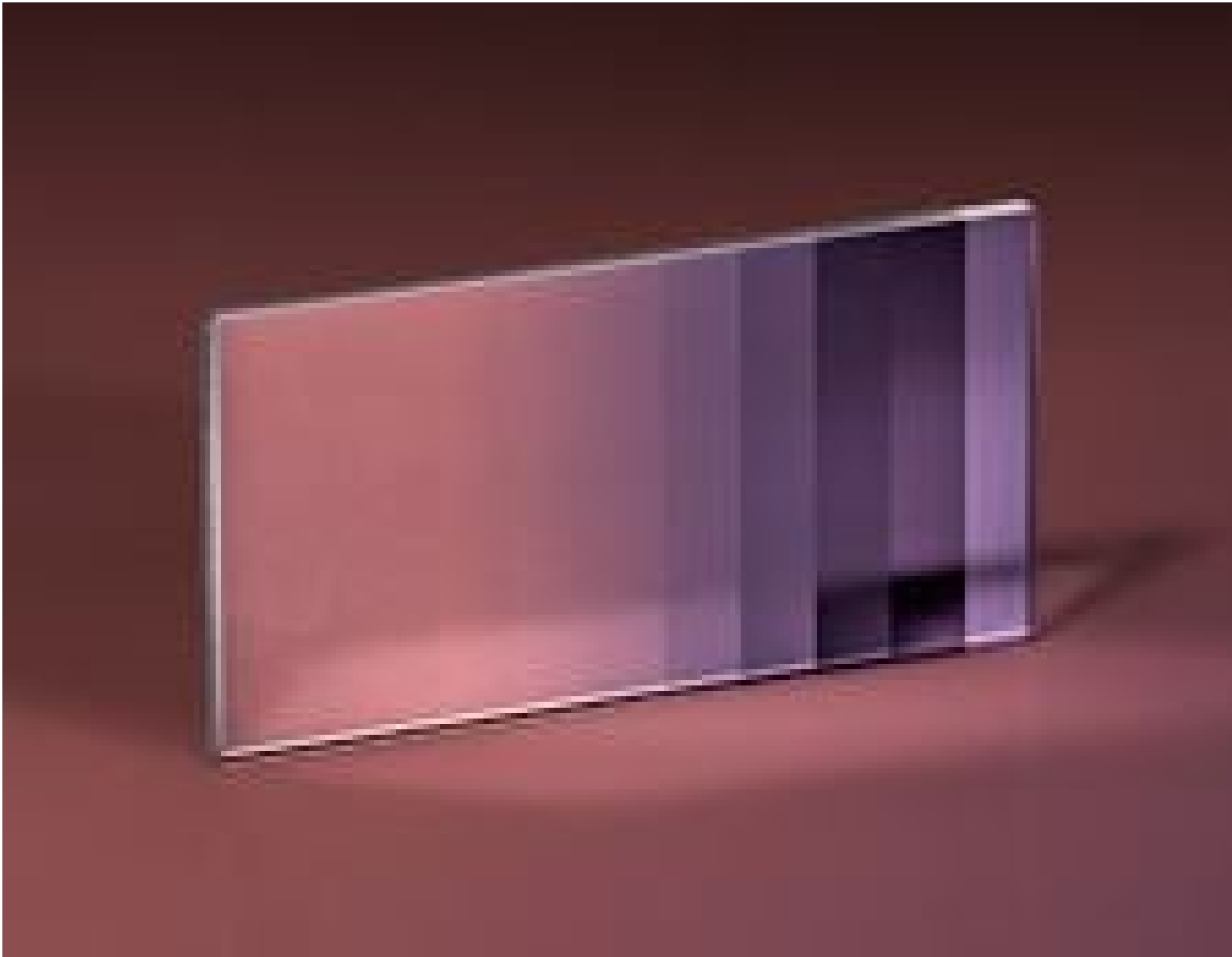

Stock #32-599 3-5 DAYS

-

1

+

S\$272.60

ADD TO CART

Qty 1-10
S\$272.60
Qty 11+
S\$245.34
Volume Pricing
Request Quote

Get Product Downloads

Dimensions (mm):
25.4 x 50.8

Optical Density OD (Average):
0.04 - 1.0

Substrate: ☐
Float Glass

Length (inches):
2.0

Length (mm): 50.80
Coating: Stepped Variable
Thickness (inches): 0.062
Type: Neutral Density Filter
Width (inches): 1.0
Width (mm): 25.40
Blocking Wavelength Range (nm): 400 - 700

Regulatory Compliance

Reach 181: Compliant
RoHS 2015: Compliant
Certificate of Conformance: View