

Prism Mount



#53-030 + Cube Beamsplitter

Stock **#53-030** 20+ In Stock

-

1

+

S\$159⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	S\$159.60 each
Qty 5-9	S\$143.64 each
Qty 10-49	S\$136.08 each
Need More?	Request Quote

Product Downloads


General	
Fixed	Type:
Cube/Prism	Type of Optics:
Physical & Mechanical Properties	
3.00	Outer Diameter (inches):

76.2	Outer Diameter (mm):
Construction: Black Anodized Aluminum with Steel Post and Delrin Clamp	
Threading & Mounting	
50.0	Size of Compatible Optics (mm):
1/4-20	Compatible Post:
Regulatory Compliance	
Compliant	RoHS 2015:
Compliant	Reach 224:
View	Certificate of Conformance:

Product Details

- Easily Secure [Prisms](#) or [Cube Beamsplitters](#)
 - Adjustable for Optics up to 55mm
 - Rotary Version Offers Manual 360° Rotation
- English Prism Mounts feature a steel post and anodized aluminum arm which eliminates obstructions in the optical path while still maintaining a secure position on the optic. Ideal for prisms and cube beamsplitters with a maximum height of 55mm, this prism mount features a V-cut clamp made of scratch resistant Delrin® to prevent damage to optics. The Prism Holder is also available as a complete assembly with the [Rotary Optic Mount](#), which allows smooth manual 360° rotation of the prism. English Prism Mounts have a locking knob that keep prisms securely positioned for increased repeatability.

Technical Information

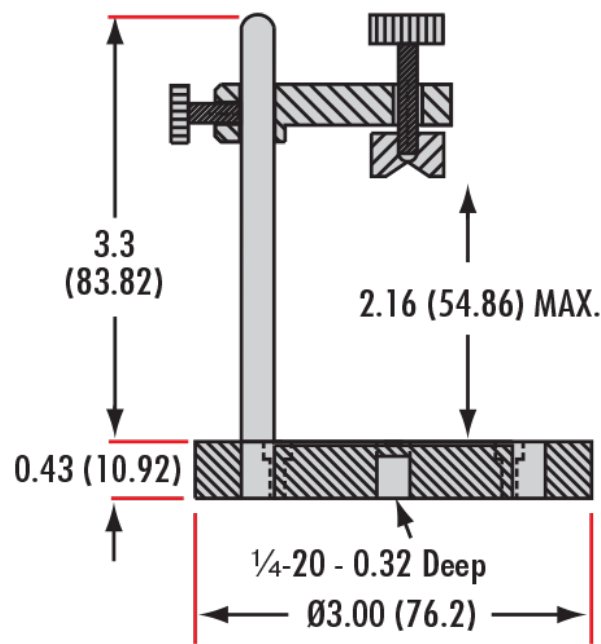

53-030