 



SCHOTT BG50, 50mm Sq., 1mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

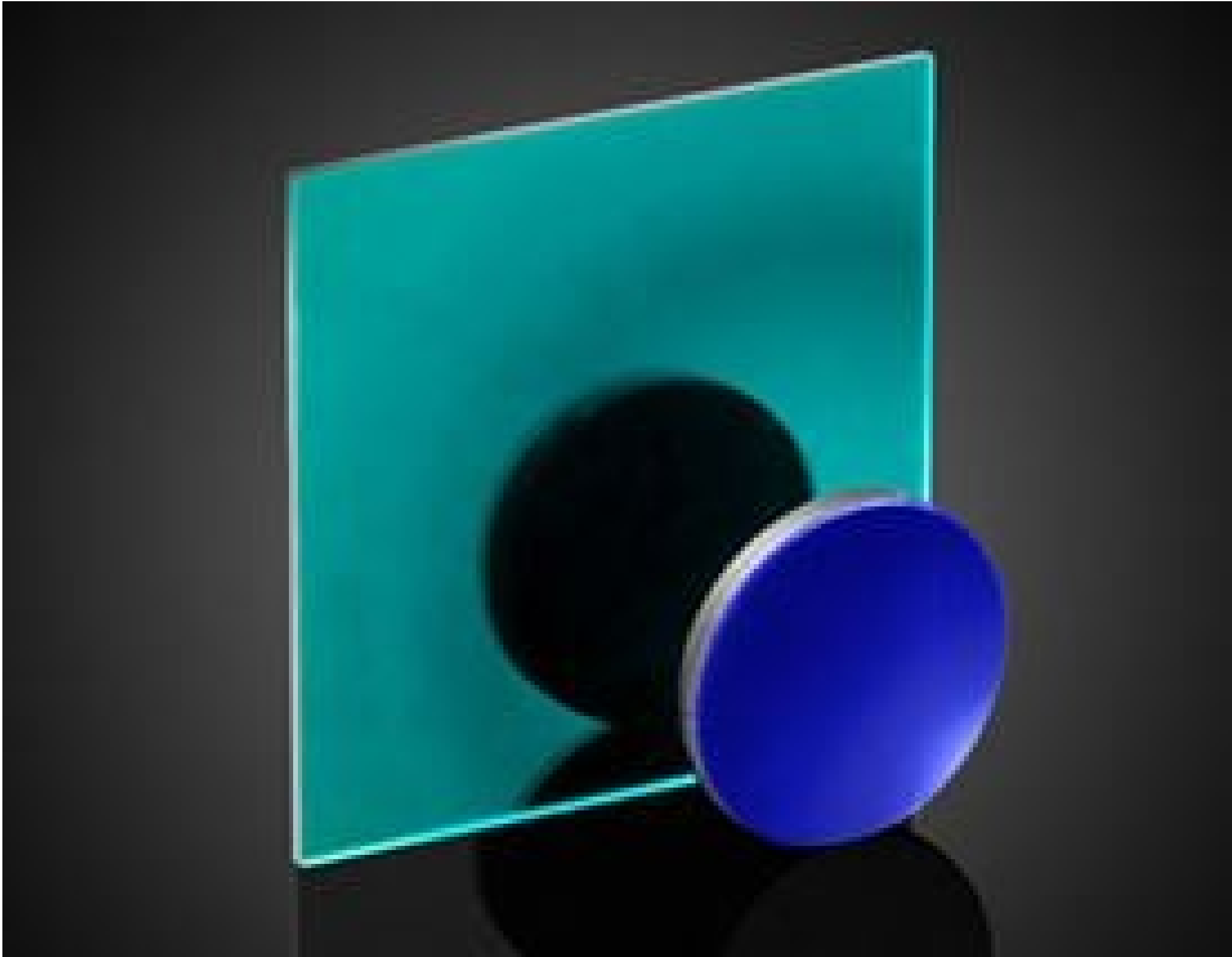

Stock #14-427 3-5 DAYS

-

1

+

S\$246.50

ADD TO CART

Qty 1-10	
S\$246.50	
Qty 11+	
S\$220.40	
Volume Pricing	
Request Quote	

Get Product Downloads
Dimensions (mm): 50.0 x 50.0
Center Wavelength CWL (nm): 500.00
Density (g/cm³):

2.61
Glass/Filter Number: SCHOTT BG50
Length (mm): 50.00
Coating: Uncoated
Color: Blue-Green
Index of Refraction n_d: 1.53
Surface Quality: 60-40
Transformation Temperature (°C): 452
Thickness (mm): 1.00 ±0.1
Type: Bandpass Filter
Wavelength: UV-Vis
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View