 



Hoya U340 (UV) 12mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

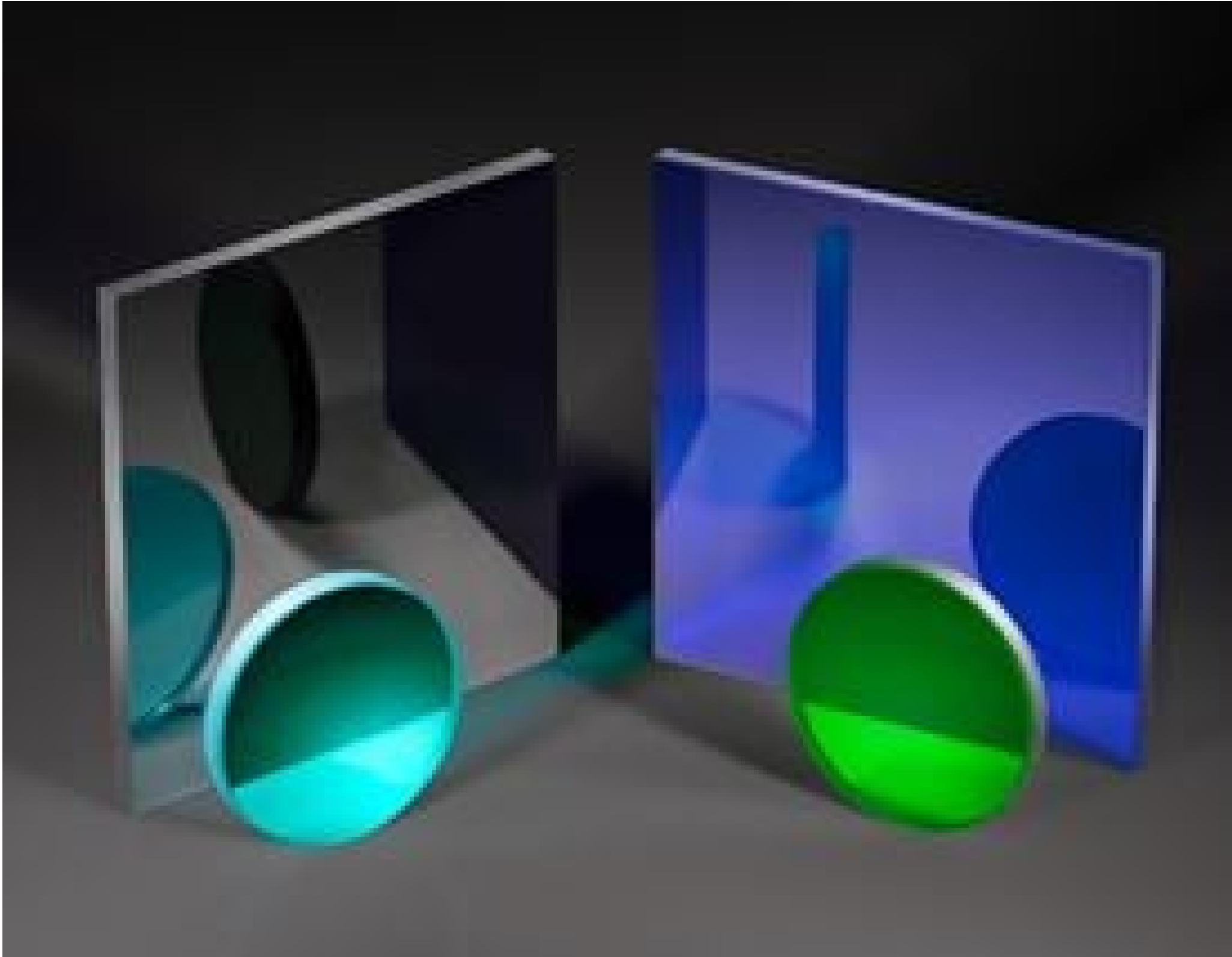

Stock **#46-096** [CONTACT US](#)

[Additional Bandwidths](#)

[-](#) 1 [+](#)

S\$59.45

ADD TO CART

Qty 1-10

S\$59.45

Qty 11+

S\$53.65

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
12.00

Center Wavelength CWL (nm):

340.00
Density (g/cm³): 2.92
Full Width-Half Max FWHM (nm): 85.00
Glass/Filter Number: Hoya U340
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View