


Variable Frequency Target 5-120 lp/mm

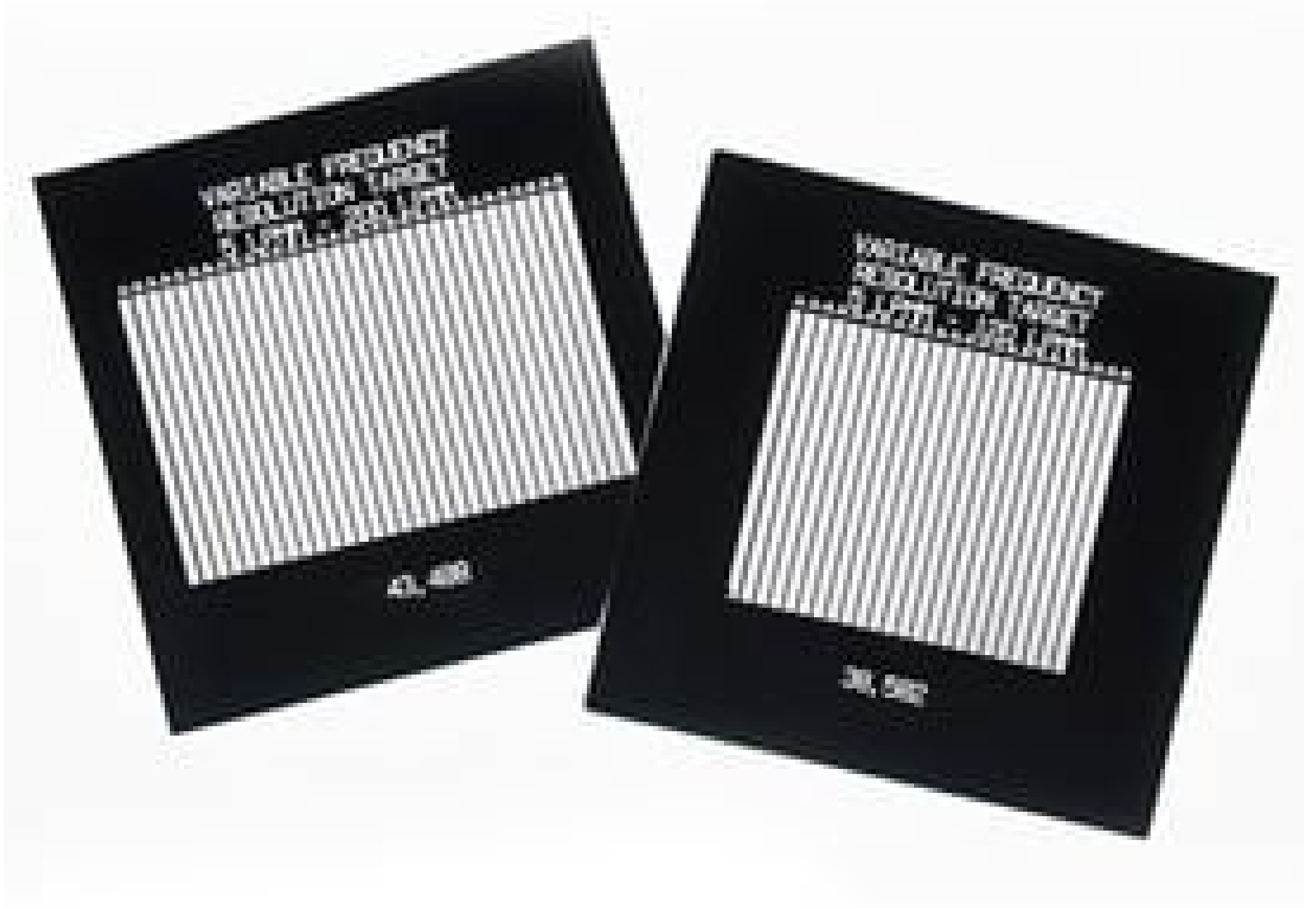

Stock #38-582 CLEARANCE 5 In Stock

S\$1,036⁰⁰

ADD TO CART

Volume Pricing

| | |
|------------|-------------------------------|
| Qty 1-4 | S\$1,036.00 each |
| Qty 5+ | S\$985.04 each |
| Need More? | Request Quote |

Product Downloads

Physical & Mechanical Properties

25.4 x 29.85 Pattern Size (mm):

2 x 2 Dimensions (inches):

1.50 Thickness (mm):

Beveled Edges:

Flatness (mm):

Optical Properties

Vacuum deposited durable chromium **Coating:**

Float Glass **Substrate:**

≥3.0 **Optical Density OD (Average):**

40-10 **Surface Quality:**

Regulatory Compliance

[Compliant](#) **RoHS 2015:**

[View](#) **Certificate of Conformance:**

[Compliant](#) **Reach 240:**

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.