


Variable Frequency Target 5-120 lp/mm

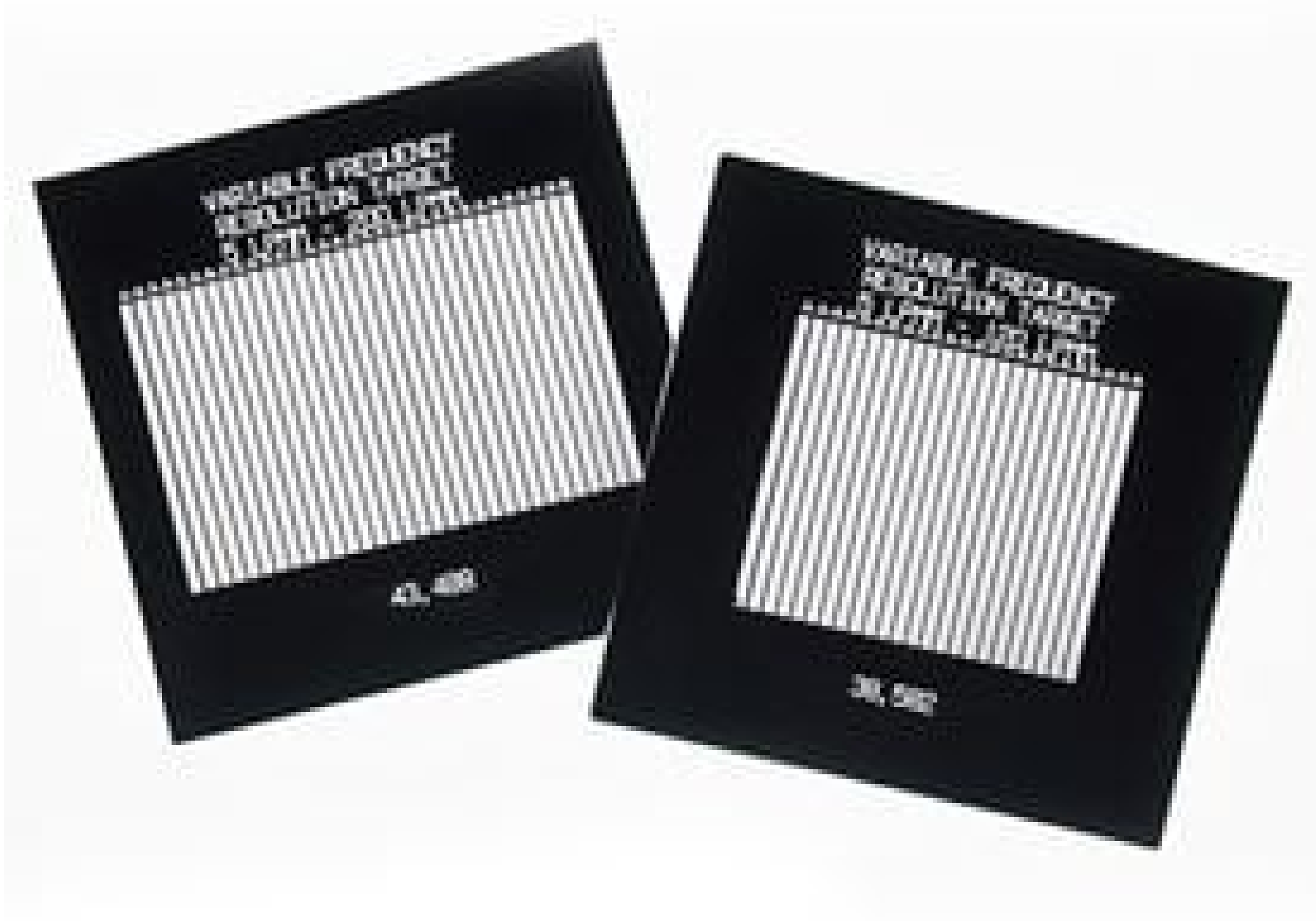

Stock **#38-582** CLEARANCE **5 In Stock**

-

1

+

S\$1,036^{.00}

ADD TO CART

Volume Pricing	
Qty 1-4	S\$1,036.00 each
Qty 5+	S\$985.04 each
Need More?	Request Quote

Product Downloads

SPECIFICATIONS

Physical & Mechanical Properties

25.4 x29.85

Pattern Size (mm):

2 x2

Dimensions (inches):

1.50

Thickness (mm):

Beveled	Edges:
0.00254	Flatness (mm):
Optical Properties	
Vacuum deposited durable chromium	Coating:
Float Glass	Substrate:
≥3.0	Optical Density OD (Average):
40-10	Surface Quality:
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 240:

PRODUCT DETAILS

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
 - 1mm Wide Step Size
 - 5 lp/mm Step Increments
 - Used to Calibrate Video Systems
 - Inspect Unknown Resolutions
- Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.