


## Variable Frequency Targets 5-200 lp/mm

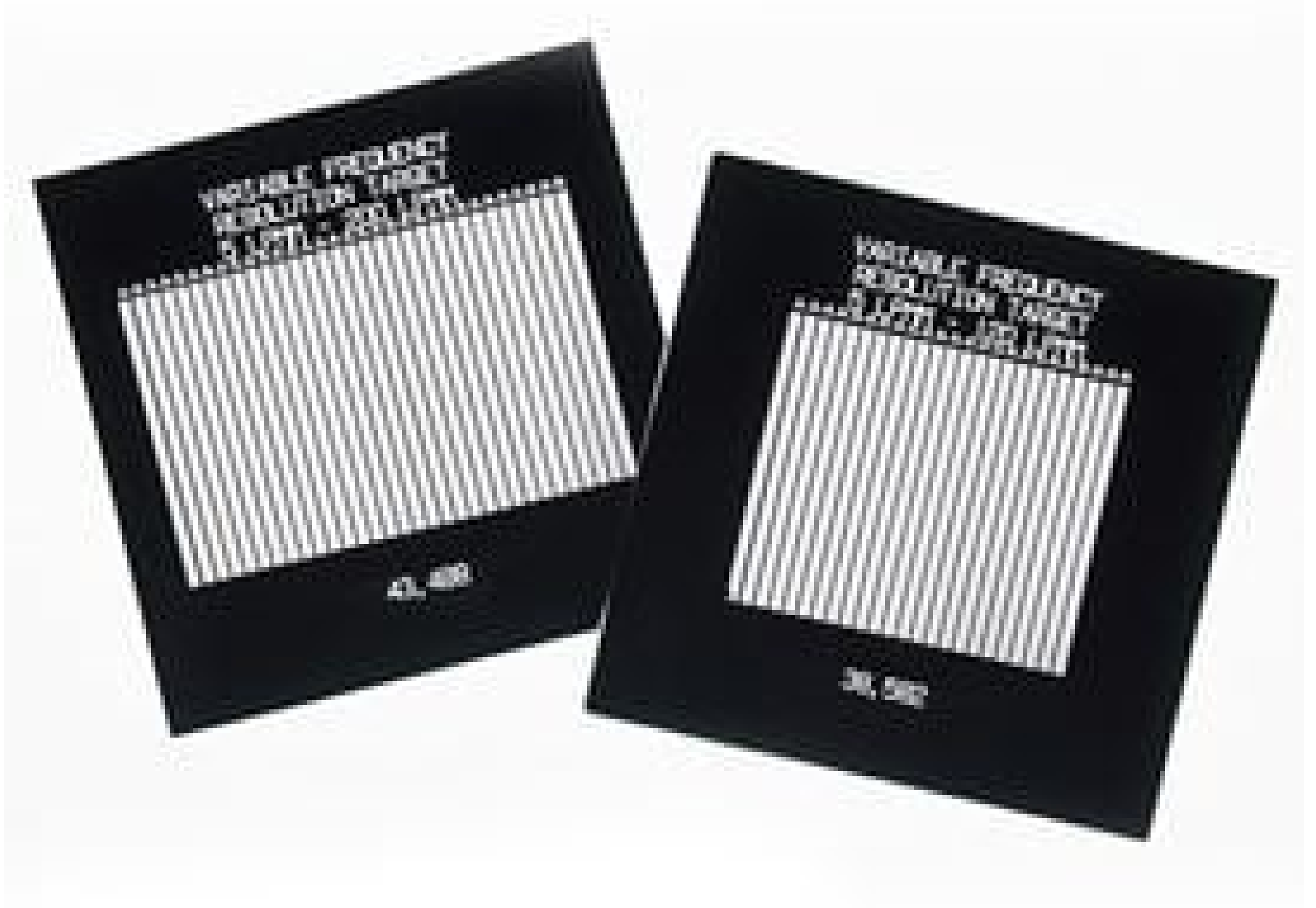

Stock #43-488 CLEARANCE 1 In Stock

S\$1,260<sup>00</sup>

ADD TO CART

### Volume Pricing

Qty 1-4	S\$1,260.00 each
Qty 5+	S\$1,197.70 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

### Physical & Mechanical Properties

25.4 x 39.37 Pattern Size (mm):

2 x 2 Dimensions (inches):

1.50 Thickness (mm):

Beveled Edges:

Flatness (mm):

0.00254

## Optical Properties

Vacuum deposited durable chromium **Coating:**

Float Glass **Substrate:**

≥3.0 **Optical Density OD (Average):**

40-10 **Surface Quality:**

## Regulatory Compliance

[Compliant](#) **RoHS 2015:**

[View](#) **Certificate of Conformance:**

[Compliant](#) **REACH 241:**

## Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.